
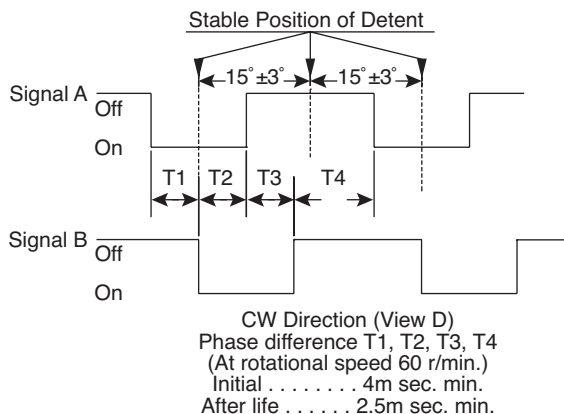


## Dimensions: mm (in.)

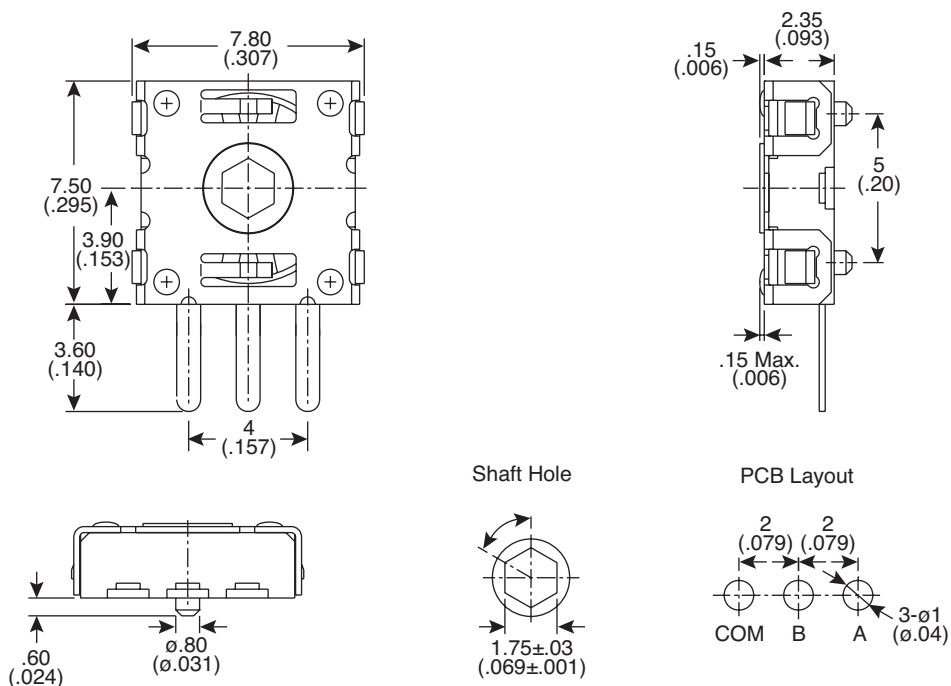

## Electrical Specifications:

- Contact Rating: 1mA/10VDC
- Contact Resistance:  $\leq 10\Omega$
- Isolation Resistance:  $\geq 50M\Omega$  50V DC
- Dielectric Strength: 50V AC 1 minute

## Mechanical Specifications:

- Operating Force: 20 ± 10gf
- Operating Temperature: -10°C ~ +60°C
- Number and Positions of Segment Points: 24 Segment points (each segment angle: 15° ± 3°)
- Output Resolution: 12 pulse/360°

## Note:

- RoHS Compliant

Encoder  
101-5439-EV

Mountain  
Switch

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

101-5439-EV