


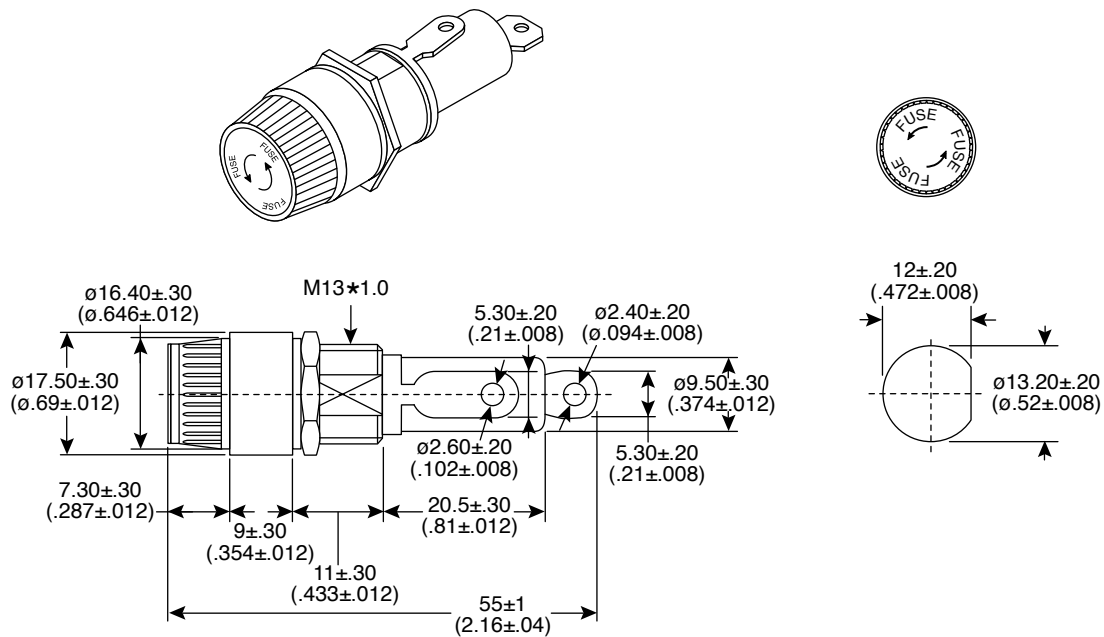

Dimensions: mm (in.)

SPECIFICATIONS	
Type:	Standard panel mount
Rating:	10A/250VAC
Insulation Resistance:	100M Ω Min. @500VDC
Dielectric Strength:	1500VAC for 1 minute
Fuse Size:	$\phi 6.35 \times 30L$, $6.35 \times 31.8L$
Cap Color:	Black
RoHS Compliant by Exemption.	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eagle Plastic Devices:](#)

[441-R314A-GRX](#)