
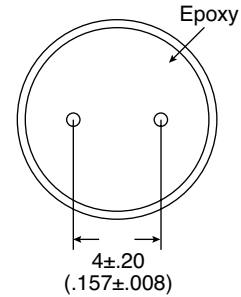
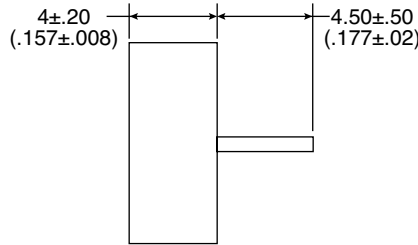
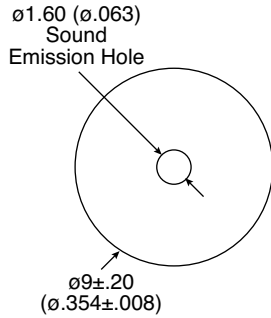
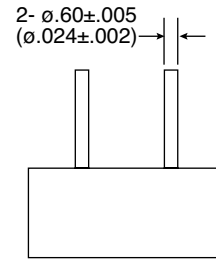



Dimensions: mm (in.)

Part Number:

254-MB555-ROX

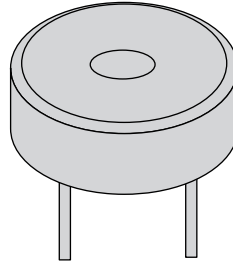

Magnetic Transducer

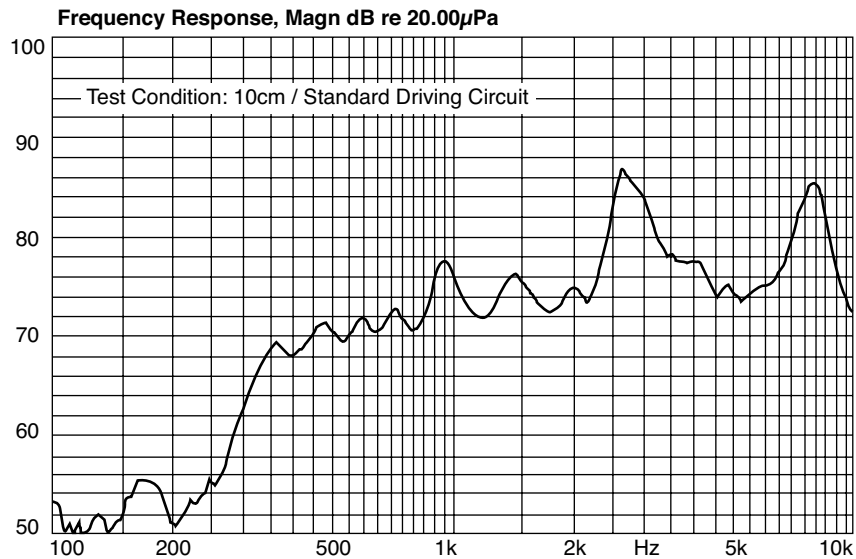

KT-400417

Electrical Specifications:

- Rated Voltage: 3.0VDC
- Operating Voltage: 2-4 V
- Resonant Frequency: 2730Hz
- Sound Pressure Level: 85dB min.
- Average Current Consumption: 80mA max.
- Coil Resistance: 15±3Ω

Materials:

- Housing: PBT
- Weight: 0.7g

Note:

- RoHS compliant by exemption

Mechanical Specifications:

- Operating Temperature: -20°C ~ +60°C
- Storage Temperature: -40°C ~ +85°C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobitone:](#)

[254-MB555-ROX](#)