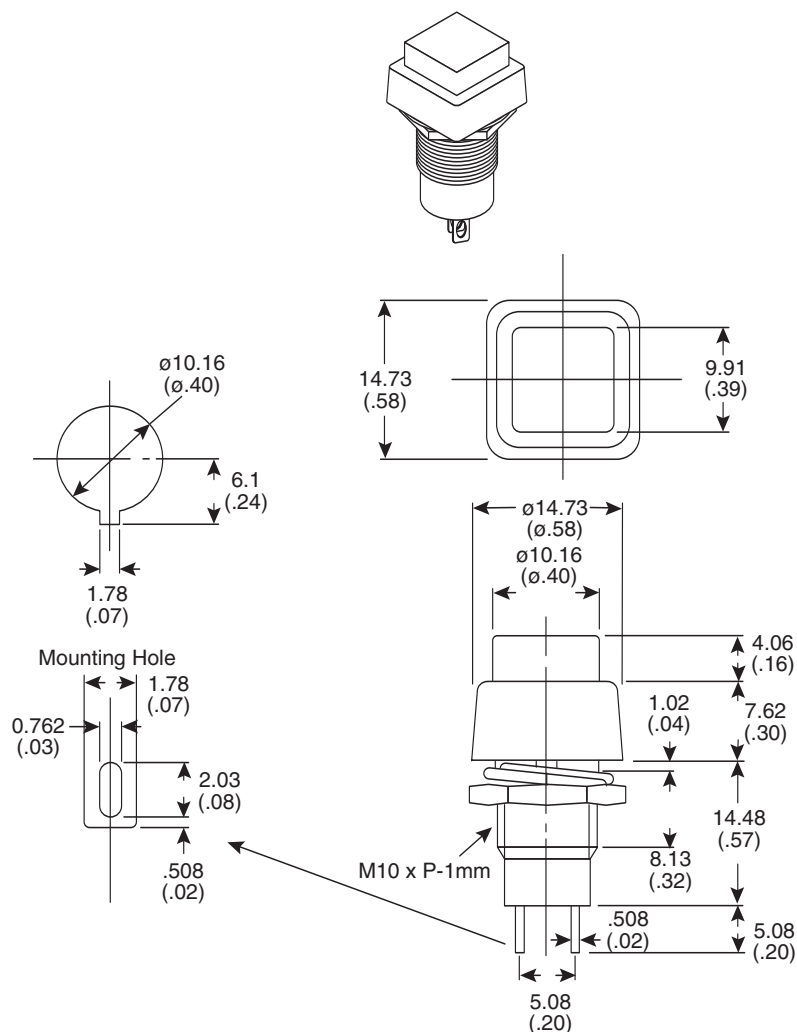


Dimensions: mm (In.)

**Mechanical Specifications:**

- Mechanical life: 100,000 operations

Electrical Specifications:

- Electrical life: 50,000 operations
- Rating: 3A / 125VAC, 1A / 250VAC
- Insulation resistance: 500VDC 100M Ω (min.)
- Dielectric strength: 1500VAC for 1 minute
- Contact resistance: 1A @ 2.5VDC 20m Ω (max.)

Mouser Stock No.	Button Color	Frame Color	Circuit
10PA332	Red	Black	Off-(On)
10PP432	Red	Black	On-Off
10PP433	Black	Black	On-Off

Pushbutton Switches
 10PA332, 10PP432, 10PP433

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[10PP432](#) [10PA332](#) [10PP433](#)