



AUDIO JACKS: STPX-3501 Series

Panel Mount 3.5mm Audio Jacks

Product Features

Audio Applications for Computers and Multimedia
Panel Mount
Eyelet Terminals
CSA/NRTL Certified File No. LR78160

Performance Specifications

Materials and Finish

Housing

PBT Thermoplastic, UL94V-0 Rated

Bushing

Brass, Nickel Plated

Terminals

Copper Alloy, Silver Plated

Electrical Characteristics

Dielectric Withstanding Voltage

500V AC RMS for 1 Minute

Mechanical Characteristics

Insertion Force

0.3kg - 3.0kg

Extraction Force

0.3kg - 3.0kg

Durability

5000 Mating Cycles

Operating Temperature

-25°C to +80°C

2D Drawing	IGES	STEP	3D PDF
Solder Profile	CofC RoHS Compliant	CofC REACH Compliant	UL Plastic File
Certificate of Origin	Check Stock	Request a Sample	Send Us An Email

Generated Part Number

Part Number Builder

	-		
Series		Number of Pins	Threading Option

Series

STPX-3501- Panel Mount 3.5mm Audio Jack

Number of Pins

3 Pins

Threading Option


C-1 - Threaded Barrel

N-1 - Non-Threaded Barrel

Contact Kycon for other options

STPX-3501

Dimensions in mm

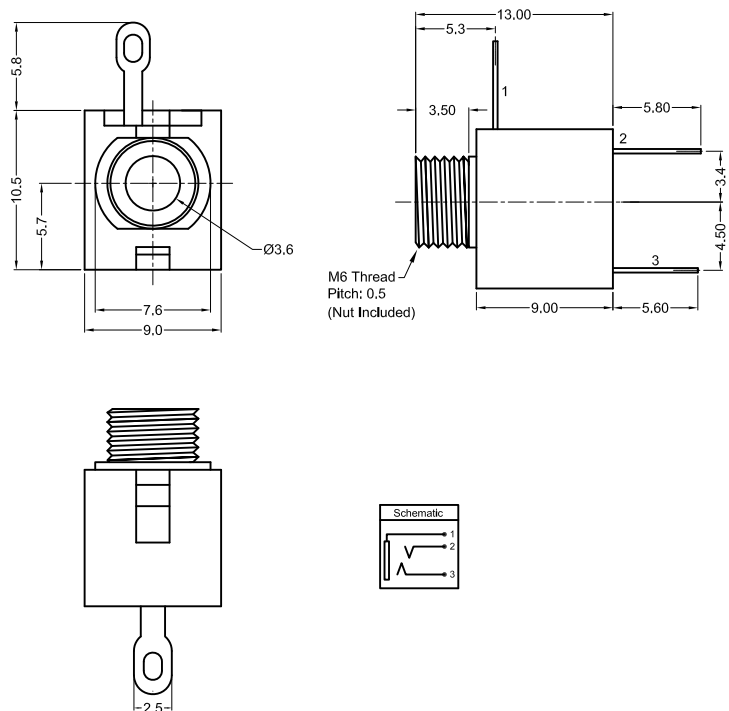

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kycon:](#)

[STPX-3501-3C](#) [STPX-3501-3N](#)