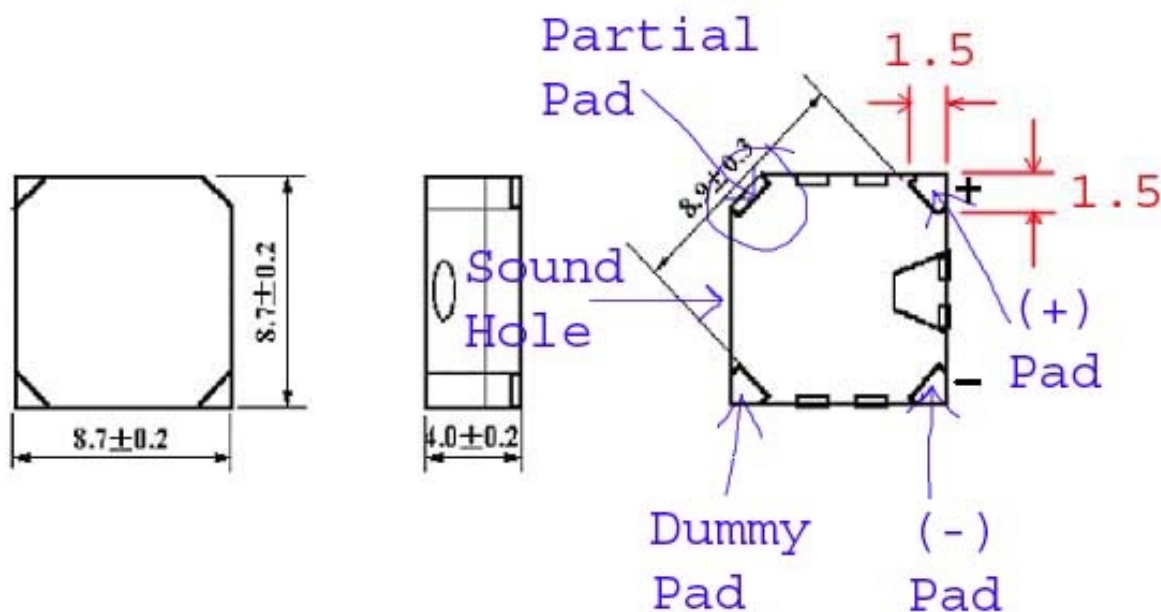


Specifications:**NO CIRCUITRY**

Oscillation Frequency (Hz)	2731
Operating Voltage (Vp-p/max)	2.0 ~ 4.0
Rated Voltage (Vp-p)	3.0
Current Consumption Max. (mA)	80 at Rated Voltage
Sound Pressure Level Min. (dB/min)	85 at 10cm at Rated Voltage
Coil Resistance (Ω)	15 ± 2
Operating Temperature ($^{\circ}\text{C}$)	$-20 \sim +85$
Storage Temperature ($^{\circ}\text{C}$)	$-30 \sim +90$
Housing	LCP plastic resin (Color : Black)
Type of Connection	SMD
Condition by reflow soldering ($^{\circ}\text{C}$)	250 ± 5 / within 5 sec
Condition by hand soldering ($^{\circ}\text{C}$)	350 ± 20 / within 5 sec
Weight (g)	0.4
Options	For other options contact factory

Dimensions: (units: mm)

PS: Vp-p = 1/2duty, square wave

RoHS Compliant

* Dummy pad and Partial Pad are connected internally and are intended to only be used to help secure the part to the circuit board.

Packaging:

Parts are supplied in tubes of 35 pieces.

Units come with wash label and are appropriate for aqueous wash.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[AST200Q](#)