

Sales Outline Drawing

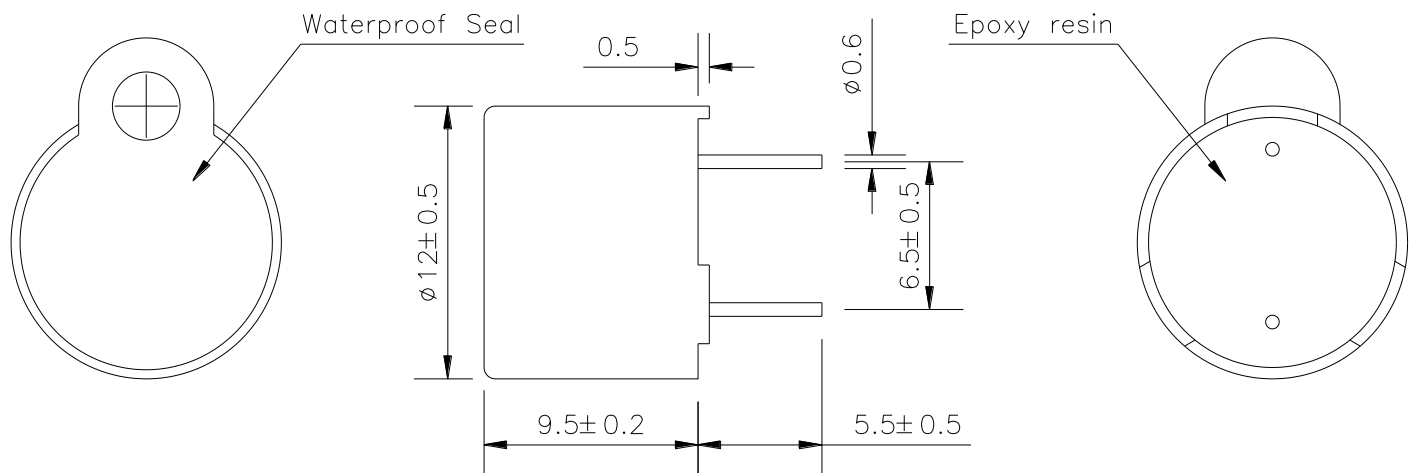
Revision

C**May not be suitable for all medical and aerospace applications.****Specifications: Contact Mallory Sonalert to discuss your application.**

Oscillation Frequency (Hz)	2600 ± 200
Operating Voltage (Vp-p)	1.1 ~ 3.0
Rated Voltage (Vp-p)	1.5
Current Consumption Max. (mA)	30 at Rated Voltage
Sound Pressure Level (dB/min)	85 at 10cm at Rated Voltage
Coil Resistance (Ω)	15 ± 3
Operating Temperature (°C)	-30 ~ +70
Storage Temperature (°C)	-40 ~ +80
Lead Pin	Tin Plated Brass
Housing	PPO plastic resin (Color : Black)
Weight (Grams)	1.6
Options	For other options contact factory

Dimensions: (units: mm)

PS: Vp-p = 1/2duty, square wave

ROHS Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PB-1226PEAQ](#)