

May not be suitable for all medical and aerospace applications.


Specifications: Contact Mallory Sonalert to discuss your application.

Oscillation Frequency (Hz)	2048
Operating Voltage (Vp-p)	8 ~ 18
Rated Voltage (Vp-p)	12
Current Consumption Max. (mA)	40 at Rated Voltage
Sound Pressure Level Min. (dB)	85 at 10cm at Rated Voltage
Coil Resistance (Ω)	145 ± 15
Operating Temperature ($^{\circ}\text{C}$)	$-40 \sim +85$
Storage Temperature ($^{\circ}\text{C}$)	$-40 \sim +85$
Condition by wave ($^{\circ}\text{C}$)	260 ± 5 / within 5 sec
Condition by hand ($^{\circ}\text{C}$)	350 ± 20 / within 5 sec
Housing	PPO plastic resin (Color: Black)
Leading Pin	Tin Plated Brass
Weight (Grams)	5.0
Options	For other options contact factory

Dimensions: (units: mm)

PS: Vp-p=1/2 duty, square wave

ROHS Compliant

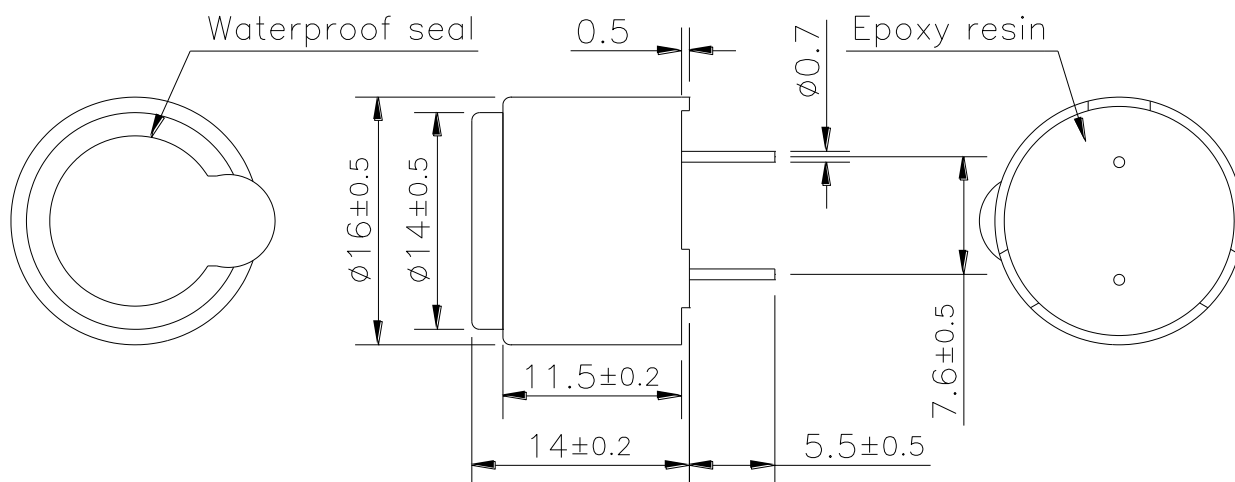

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PB-1622PQ](#)