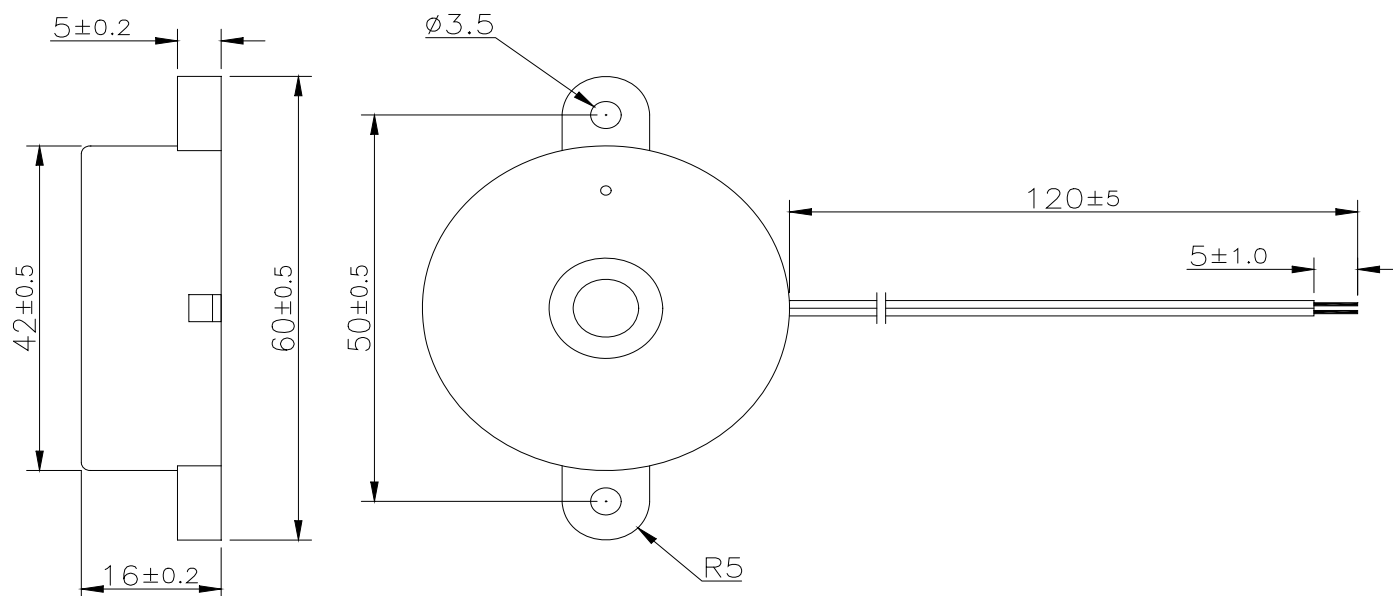


**Sales Outline Drawing**

Revision

**C****Specifications:**

|                               |                                                |
|-------------------------------|------------------------------------------------|
| Resonant Frequency (Hz)       | 2500 ~ 3500                                    |
| Operating Voltage (Vdc)       | 5 ~ 15                                         |
| Rated Voltage (Vdc)           | 12                                             |
| Current Consumption (mA/max)  | 40 at Rated Voltage                            |
| Sound Pressure Level (dB/min) | 100 at 100cm at Rated voltage                  |
| Tone/Pulse Rate (Hz0)         | Hi/Low 1.2 ±20%                                |
| Operating Temperature (°C)    | -20 ~ +70                                      |
| Storage Temperature (°C)      | -30 ~ +80                                      |
| Housing                       | ABS 757 UL94HB plastic resin<br>(Color: Black) |
| Lead Wire                     | 28 AWG                                         |
| Weight (Grams)                | 17.8                                           |
| Options                       | For other options contact factory              |

**Dimensions:** (units: mm)**ROHS Compliant**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PS-562Q](#)