



Mallory Sonalert Products, Inc.

Part #:

SBT200PC

Sales Outline Drawing

Revision:

C

Specifications:

cUL Recognized as Capable of meeting Medical Spec IEC60601-1-8

Capacitance (pF):	70,000 $\pm$ 30% at 120 Hz
Rated Voltage (Vp-p):	5, 30 Max
Current Draw:	1.5 mA at rated voltage
Recommended Drive	200 Hz
Loudness @ 10 CM:	85 to 95 dB(A) Typ.
Harmonics Present:	Minimum of 4 peaks within $\pm$ 15dB from 1-4kHz
Housing Material:	ABS 777D Plastic Resin, Black
Lead Pin:	Tin Plated Brass
Storage Temperature:	-40° to +85° C
Operating Temperature:	-30° to +65° C
Weight (Typical):	0.56 oz (16g)
Options:	Please contact factory.

Dimensions: Inches [mm]


cUL Recognized

ROHS Compliant

PATENT NUMBER: 7880593

Before Code Date: 1546 Not cUL Recognized

After Code Date: 1547 cUL Recognized

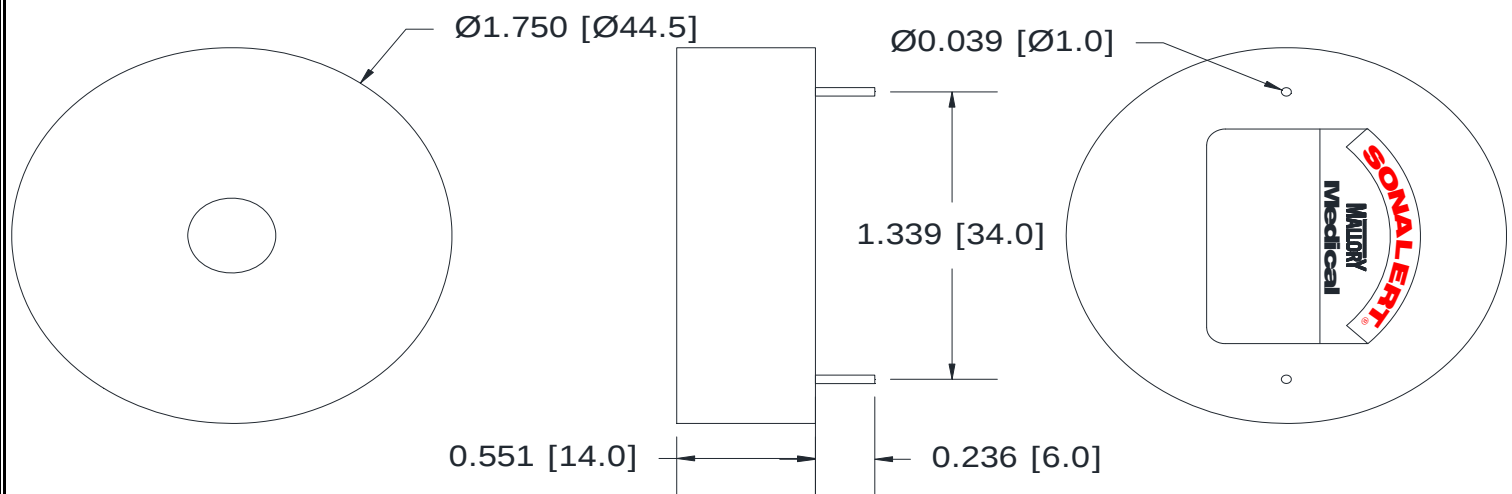

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[SBT200PC](#)