


2.5mm In-Line Stereo Jack



161-2225-EX



2.5mm In-Line Stereo Jack

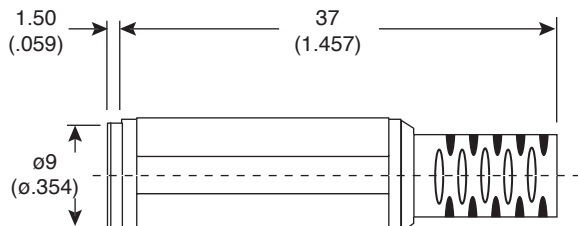

Dimensions: mm (In.)

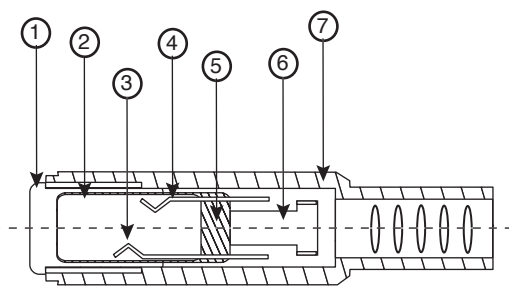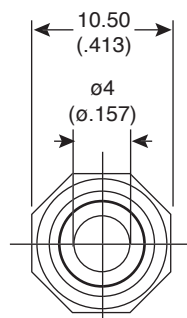

	Part Name	Material	Finish
1	Body	Brass	--
2	Insulator	PVC	--
3	Contact A	PBS	Au
4	Contact B	PBS	Ni
5	Base	ABS	--
6	Terminal	Brass	Ni
7	Cap	PE	--

Specifications

Contact resistance:	30mΩ max.
Insulation resistance:	100MΩ min.@500 VDC
Dielectric strength:	500 VAC for one minute
Life cycles:	5,000 cycles min.
Tolerance :	±0.3
Max O.D. wire:	3.8mm
RoHS Compliant by Exemption	

Date Last Revised: 12-1-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300826

161-2225-EX

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[161-2225-EX](#)