


Locking DC Power Plugs for Molding

171-0722-E , 171-0726-E

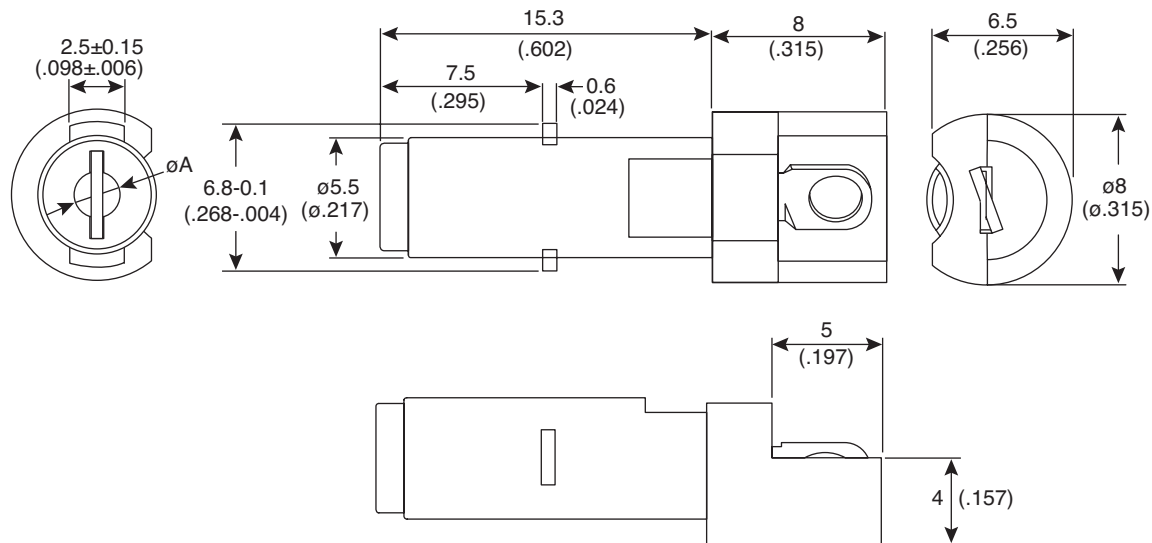

Dimensions: mm (In)

MOUSER STOCK NO.	Dimension A
171-0722-E	ø2.1mm
171-0726-E	ø2.5mm

SPECIFICATIONS	
Rating:	171-0722-E - 12VDC 0.5A; 171-0726-E - 12VDC 1A
Dielectric Strength:	500VAC for 1 Minute
Insulation Resistance:	100MΩ min. @ 500VDC
Contact Terminal:	Nickel Plated Phosphor Bronze
Sleeve:	Nickel Plated Brass
Insulator:	Noryl Type SE1
RoHS Compliant	

Date Last Revised: 4-6-06

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300898

Locking DC Power Plugs for Molding

171-0722-E, 171-0726-E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[171-0726-E](#) [171-0722-E](#)