

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0019092038](#)
Status: **Active**
Overview: [Standard .093" Pin and Socket Connectors](#)
Description: 2.36mm Diameter Standard .093" Pin and Socket Plug Housing with Positive Latch, UL 94V-2, with Panel Mount, 3 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[3D Model \(PDF\)](#)
[Product Specification PS-3191-001-001 \(PDF\)](#)
[Packaging Specification 31910001-PK-000 \(PDF\)](#)
[Packaging Specification PK-3191-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR19980
UL E29179

General
Product Family Crimp Housings
Series [3191](#)
Application Power, Wire-to-Wire
Comments Polarized to Mating Part, with Mounting Ears
Overview [Standard .093" Pin and Socket Connectors](#)
Product Name Standard .093"
UPC 800753594173


Physical
Breakaway No
Circuits (maximum) 3
Circuits Detail 1x3
Color - Resin Natural
Flammability 94V-2
Gender Plug
Glow-Wire Capable No
Keying to Mating Part None
Lock to Mating Part Yes
Material - Resin Nylon
Net Weight 3.716/g
Number of Rows 1
Packaging Type Bag
Panel Mount Yes
Pitch - Mating Interface 6.70mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C

Electrical
Current - Maximum per Contact 11.0A

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number 3191-3P

Reference - Drawing Numbers
[Packaging Specification](#) 31910001-PK-000, PK-3191-001-001
[Product Specification](#) PS-3191-001-001
[Sales Drawing](#) SD-3191-3X-001, SD-3191-3X-002, SD-3191-3X-003

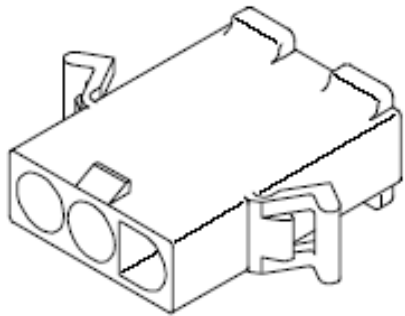

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[3191](#) Series

Mates With

[19091036](#) , [19091039](#) , [19095039](#) , [5219](#)

Use With

Standard .093" Female Crimp Terminals
[1189](#) , [1381](#) , [1433](#) , [4550](#) . Standard .093"
Male Crimp Terminals [1190](#) , [1380](#) , [1434](#) ,
[1973](#) , [42138](#)

This document was generated on 08/30/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19-09-2038