

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0039014051

Status:

Active

Overview:


Mini-Fit Family Power Connectors

Description:

Mini-Fit Jr. Receptacle Housing, Single Row, 5 Circuits, UL 94V-0, Natural

Documents:	
Drawing (PDF)	Product Specification PS-5556-002-001 (PDF)
3D Model	Application Specification 55560001-AS-000 (PDF)
3D Model (PDF)	Application Specification AS-5557-001-001 (PDF)
Product Specification 55560002-PS-CH-000 (PDF)	Packaging Specification PK-5557-002-000 (PDF)
Product Specification 55560002-PS-ES-000 (PDF)	Test Summary 55560010-TS-000 (PDF)
Product Specification 55560002-PS-SK-000 (PDF)	Test Summary 55570000-TS-000 (PDF)
Product Specification PS-45750-001-001 (PDF)	Test Summary TS-5556-002-001 (PDF)
Product Specification PS-5556-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	5557
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	Current = 13A max. per circuit when header is mated to a receptacle loaded with 45750 series terminals crimped to 16 AWG wire. . See Molex product specification PS-45750-001 for additional current derating information.. See Molex product specification.
Overview	Mini-Fit Family Power Connectors
Product Name	Mini-Fit Jr.
UPC	800753584112
Physical	
Breakaway	No
Circuits (maximum)	5
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.400/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Electrical	
Current - Maximum per Contact	13.0A
Solder Process Data	
Lead-freeProcess Capability	N/A

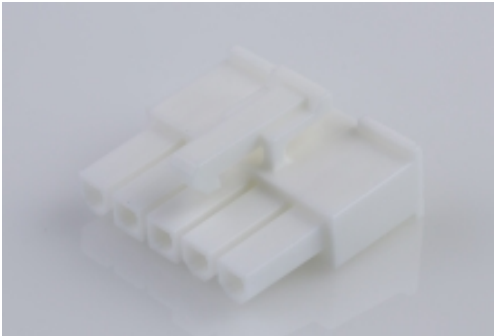

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

5557 Series

Mates With

[39014053](#) Panel Mount Plug, [39014057](#) Free Hanging Plug, [39302056](#) Vertical Header, [39302058](#) Vertical Header, [39303056](#) Right Angle Header

Use With

Mini-Fit Female Crimp Terminals [5556](#)

Mini-Fit Plus HCS Crimp Terminal [45750](#)
Mini-Fit Pre-Crimped Leads [797580001](#) , [797580009](#)

Material Info

Engineering Number 5557-05R2-210

Reference - Drawing Numbers

Application Specification 55560001-AS-000, AS-5557-001-001
Packaging Specification PK-5557-002-000
Product Specification 55560002-PS-CH-000, 55560002-PS-ES-000,
55560002-PS-SK-000, PS-45750-001-001,
PS-5556-001-001, PS-5556-002-001
Sales Drawing 55570002-SD-000
Test Summary 55560010-TS-000, 55570000-TS-000,
TS-5556-002-001

This document was generated on 09/01/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39-01-4051](#)