

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0050579508

Status:


Active

Overview:

SL Modular Connectors

Description:

SL Crimp Housing, Single Row, Version H, Polarized Friction Lock, 8 Circuits, Black

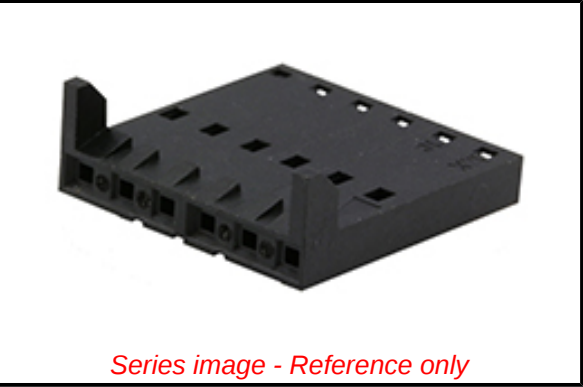

Documents:	
3D Model	Product Specification PS-71851-001 (PDF)
Drawing (PDF)	Packaging Specification PK-70066-100-001 (PDF)
3D Model (PDF)	Test Summary TS-70058-001-001 (PDF)
Product Specification PS-70058-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-70400-001 (PDF)	

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70066
Application	Signal, Wire-to-Board
Comments	Version H
Overview	SL Modular Connectors
Product Name	SL
UPC	800754381413
Physical	
Circuits (maximum)	8
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester Alloy
Net Weight	0.732/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	700660217
Reference - Drawing Numbers	
Packaging Specification	PK-70066-100-001
Product Specification	PS-70058-001, PS-70400-001, PS-71851-001
Sales Drawing	SD-70066-0211-0234-001
Test Summary	TS-70058-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

70066 Series

Mates With

6373 Straight Header, 7478 , 171856 , 171857

Use With

SL Crimp Terminal 70058 , 71851

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

50-57-9508