

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191210056
Status: Active
Overview: Solderless Terminals
Description: InsulKrimp Flanged Spade Tongue Terminal for 10-12 AWG Wire, Stud Size 10 (M5), Width 9.53mm

Documents:
Product Specification PS-19902-009-001 (PDF) Product Specification PS-19902-013-001 (PDF)
Product Specification PS-19902-011-001 (PDF) RoHS Certificate of Compliance (PDF)

Agency Certification
CSA LR18689
UL E32244


General
Product Family Ring and Spade Terminals
Series 19121
Crimp Quality Equipment Yes
Overview Solderless Terminals
Product Name InsulKrimp
Type Spade
UPC 800753096073

Physical
Barrel Type Closed
Color - Resin Yellow
Flammability 94V-0
Insulation PVC
Material - Plating Mating Tin
Net Weight 2.624/g
Packaging Type Bag
Stud Size 10 (M5)
Wire Insulation Diameter 6.35mm
Wire Size AWG 10, 12
Wire Size mm² 4.00-6.00

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number C-217-10X

Reference - Drawing Numbers
Product Specification PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19121-001

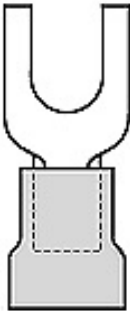

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Not Reviewed
REACH SVHC
Contained Per -
ED/71/2019 (16 July
2019)
Di-(2-
ethylhexyl)phthalat
Halogen-Free
Status
Not Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
19121 Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	640010100
PremiumGrade Hand Crimp Tool for	640010300

Insulkrimp Terminals
and Splices, 10-22
AWG (Rings,
Spades, Hooks,
Block Spades and
Flanged Spades)
Crimp Head for the 640050100
AT-200 Pneumatic
Hand Tool
Crimp Head for the 640050300
AT-200 Pneumatic
Hand Tool
ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 07/02/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19121-0056](#)