

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0191640061](#)  
**Status:** **Active**  
**Overview:** [Perma-Seal Terminals](#)  
**Description:** Perma-Seal Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 6 (M3.5)

**Documents:**

[3D Model](#) [Product Specification PS-19902-013-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series [19164](#)  
 Crimp Quality Equipment Yes  
 Mil-Spec N/A  
 Overview [Perma-Seal Terminals](#)  
 Product Name Perma-Seal  
 Type Ring  
 UPC 800753113466

**Physical**


Barrel Type Closed  
 Insulation NiAc  
 Material - Plating Mating Tin  
 Net Weight 2.042/g  
 Packaging Type Bag  
 Plating min - Mating 2.540µm  
 Plating min - Termination 2.540µm  
 Stud Size 6 (M3.5)  
 Wire Insulation Diameter 7.87mm  
 Wire Size AWG 10, 12  
 Wire Size mm<sup>2</sup> 3.09-5.01

**Material Info**

Engineering Number SC-228-06

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001, PS-19902-013-001  
 Sales Drawing SD-19164-041

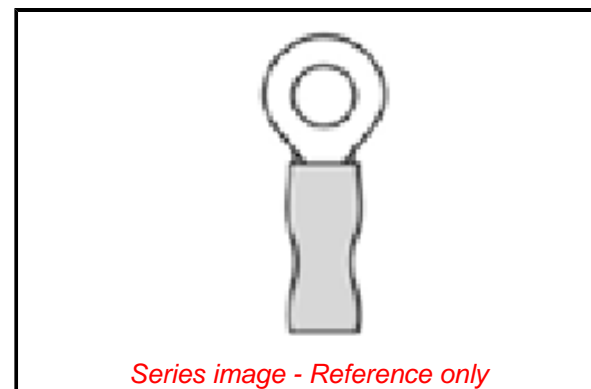

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/61/2018 (27 June  
 2018)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[19164 Series](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19164-0061](#)