

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0309681247

Status:


Active

Overview:

H-DAC 64 Unsealed Connector System

Description:

2.54mm Pitch, 0.64mm Width H-DAC 64 Hybrid Male High Density Automotive Crimp Housing, Dual Row, 24 Circuits, Polarization Option A, Gray

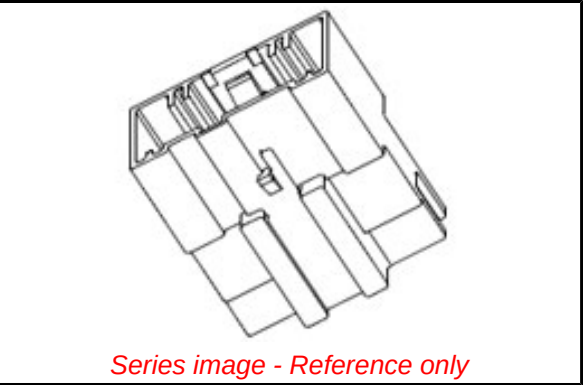

Documents:	
3D Model	Product Specification PS-30968-024-001 (PDF)
Drawing (PDF)	Packaging Specification PK-30907-760-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	30968
Application	Automotive, Power, Wire-to-Wire
Comments	Polarization Option A
Overview	H-DAC 64 Unsealed Connector System
Polarization	A
Product Name	H-DAC 64
UPC	822348858958
Physical	
Circuits (maximum)	24
Color - Resin	Gray
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Modified Polystyrene
Net Weight	16.432/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +100°C
Electrical	
Current - Maximum per Contact	7.0A
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-30907-760-001
Product Specification	PS-30968-024-001
Sales Drawing	SD-30968-124-001

EU ELV
Compliant

EU RoHS
Compliant

REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free
Status
Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image
Compliant

Not Contained

Search Parts in this Series

30968 Series

Mates With

30700 , 31389 H-DAC 64 High Density Automotive Connectors

Use With

Contact Molex for Terminal information.

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[30968-1247](#)