

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0366970001
Status: Active
Overview: HandyLink™ I/O Interconnect System
Description: HandyLink®-to-HandyLink® Cable Assembly, Straight Overmold, 1.0m Cable Length


Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-36697-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	36697
Assembly Configuration	Dual Ended Connectors
Comments	Please reference Application Specification AS-44828-001 when designing
Connector to Connector	HandyLink®-to-HandyLink®
Overview	HandyLink™ I/O Interconnect System
Product Name	HandyLink®
UPC	822350242554
Physical	
Cable Length	1.0m
Circuits (Loaded)	16
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	High Performance Alloy (HPA), Stainless Steel
Material - Plating Mating	Gold, Tin
Material - Plating Termination	Tin
Net Weight	55.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.80mm
Plating min - Mating	0.102µm, 1.270µm
Plating min - Termination	1.270µm, 5.080µm
Single Ended	No
Termination Interface: Style	Solder or Weld
Wire Insulation Diameter	0.70-1.15mm (.026-.045")
Wire Size AWG	30
Wire/Cable Type	PVC

Electrical	
Current - Maximum per Contact	1.5A
Shielded	No
Voltage - Maximum	30V

Material Info

Reference - Drawing Numbers	
Product Specification	PS-36697-001
Sales Drawing	SD-36697-001

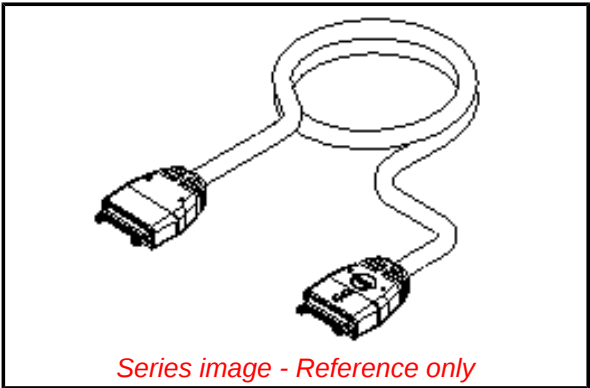

EU ELV Not Reviewed	
EU RoHS Not Reviewed	China RoHS
REACH SVHC Not Reviewed	
Halogen-Free Status Not Reviewed	
Need more information on product environmental compliance?	
Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	
China ROHS	Not Reviewed
ELV	Not Reviewed

Search Parts in this Series
36697 Series

Mates With
44828 HandyLink® Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[36697-0001](#)