

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0393570004

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

3.50mm Pitch Beau Eurostyle Fixed Mount PCB Terminal Block, 4 Circuits

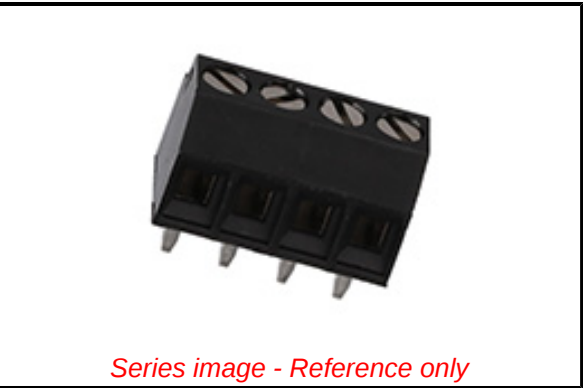

Series image - Reference only

Documents:	
3D Model (PDF)	3D Model
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39357
Application	N/A
Component Type	One Piece
Overview	Eurostyle Terminal Blocks
Product Name	Eurostyle Fixed Mount
Type	Euro Block
UPC	756054634141
Physical	
Circuits (Loaded)	4
Circuits (maximum)	4
Entry Angle	Horizontal
Flammability	94V-0
Lock to Mating Part	None
Net Weight	2.000/g
Number of Rows	1
Orientation	Vertical
PC Tail Length	3.50mm
PCB Retention	None
PCB Thickness - Recommended	1.60mm
Panel Mount	No
Pitch - Mating Interface	3.50mm
Pitch - Termination Interface	3.50mm
Polarized to Mating Part	No
Shrouded	Fully
Stackable	Yes
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-30° to +85°C
Wire Size AWG	16, 18, 20, 22, 24, 26, 28
Wire Size mm²	0.08-1.31
Electrical	
Current - Maximum per Contact	17.5A
Voltage - Maximum	300V
Material Info	
Engineering Number	MX-MTB04008-0N
Reference - Drawing Numbers	
Sales Drawing	SD-39357-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[39357](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39357-0004](#)