

LOW PROFILE SHIELDED SMD POWER INDUCTORS

ASPI-104S



RoHS
Compliant



10.3 x 10.4 x 4.0 mm

FEATURES:

- Superior to be high saturation for high density surface mounting
- High energy storage and Low resistance to keep power loss minimum
- Magnetically shielded with ferrite core for low radiation
- Suitable for RoHS compliant reflow

APPLICATIONS:

- Desktop, notebook, servers
- Network hubs, bridges, routers
- XDSL, PBX base stations
- Power source circuits, DC/DC converters, DC/AC inverters
- Digital TV, DVD, Modem, setup box
- Battery charger

STANDARD SPECIFICATIONS:

PARAMETERS

ABRACON P/N:	ASPI-104S xxx Series
Operating temperature:	-40°C to +125°C
Storage temperature:	+15°C to +28°C (while in packaging)
Storage temperature:	-40°C to +125°C (outside of packaging)

PART NUMBER	INDUCTANCE (uH)	Tolerance	R _{DC} (mΩ) max	I _{DC} (A) max
ASPI-104S-R56	0.56	N	8	10.00
ASPI-104S-1R0	1.0	N	8	10.00
ASPI-104S-1R2	1.2	N	8	10.00
ASPI-104S-1R3	1.3	N	8	10.00
ASPI-104S-1R5	1.5	N	8	10.00
ASPI-104S-1R8	1.8	N	10	9.50
ASPI-104S-2R2	2.2	N	11	8.00
ASPI-104S-2R5	2.5	N	12	7.50
ASPI-104S-2R7	2.7	N	12	7.50
ASPI-104S-3R3	3.3	N	13	6.50
ASPI-104S-3R8	3.8	N	17	6.00
ASPI-104S-4R7	4.7	N	21	5.70
ASPI-104S-5R0	5.0	N	22	5.60
ASPI-104S-5R2	5.2	N	22	5.50
ASPI-104S-5R6	5.6	M, N	25	5.20
ASPI-104S-6R8	6.8	M, N	26	4.90
ASPI-104S-7R0	7.0	M, N	27	4.80
ASPI-104S-8R2	8.2	M, N	33	4.60
ASPI-104S-100	10	M, N	35	4.40
ASPI-104S-120	12	M, N	46	3.92
ASPI-104S-150	15	M, N	50	3.60
ASPI-104S-180	18	M, N	70	3.00
ASPI-104S-220	22	M, N	73	2.90
ASPI-104S-270	27	M, N	83	2.80
ASPI-104S-330	33	M, N	93	2.30
ASPI-104S-390	39	M, N	120	2.20
ASPI-104S-470	47	M, N	128	2.10
ASPI-104S-560	56	M, N	171	1.80

LOW PROFILE SHIELDED SMD POWER INDUCTORS

ASPI-104S



RoHS
Compliant



10.3 x 10.4 x 4.0 mm

STANDARD SPECIFICATIONS CONT:

PART NUMBER	INDUCTANCE (μ H)	Tolerance	R _{DC} (m Ω) max	I _{DC} (A) max
ASPI-104S-680	68	M, N	213	1.50
ASPI-104S-820	82	M, N	250	1.40
ASPI-104S-101	100	M, N	304	1.35
ASPI-104S-121	120	M, N	400	1.20
ASPI-104S-151	150	M, N	506	1.15
ASPI-104S-181	180	M, N	631	1.03
ASPI-104S-221	220	M, N	756	0.92
ASPI-104S-271	270	M, N	853	0.84
ASPI-104S-331	330	M, N	1090	0.70
ASPI-104S-391	390	M, N	1450	0.62
ASPI-104S-471	470	M, N	1520	0.54
ASPI-104S-561	560	M, N	2500	0.50
ASPI-104S-681	680	M, N	2800	0.45
ASPI-104S-821	820	M, N	3000	0.40
ASPI-104S-102	1000	M, N	3250	0.32


Test Conditions

Inductance: 100kHz

I_{DC}: The current when the inductance becomes 35% lower than its initial value or the actual current when the temperature of coil increases to $\Delta T=40^{\circ}\text{C}$. The smaller one is defined as Rated DC Current. ($T_a=25^{\circ}\text{C}$)

OPTIONS AND PART IDENTIFICATION:

(Left blank if standard)

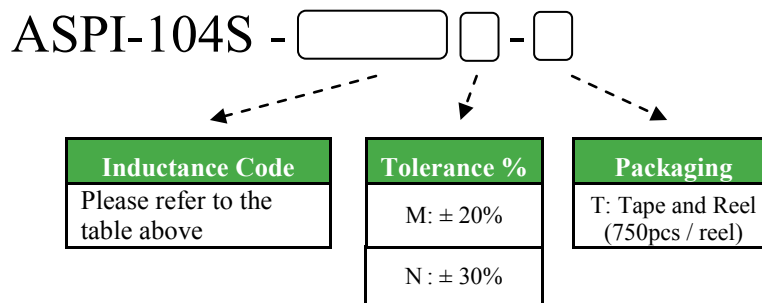

LOW PROFILE SHIELDED SMD POWER INDUCTORS




10.3 x 10.4 x 4.0 mm

ASPI-104S




RoHS
Compliant

➤ **OUTLINE DIMENSIONS:**

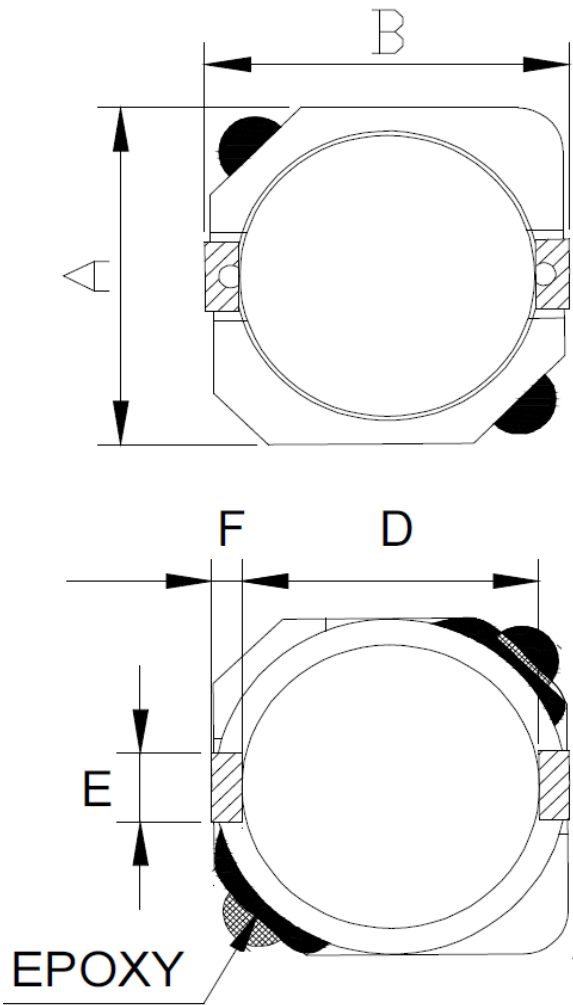

Recommended Land Pattern

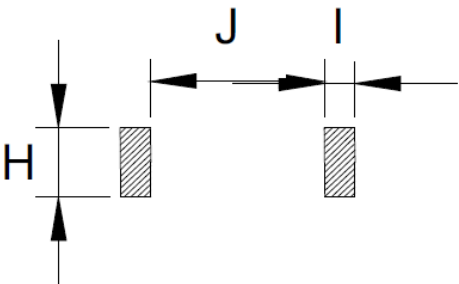

A Max.	B Max.	C Max.	D	E	F	H	I	J
10.3	10.4	4.0	7.7	3.0	1.2	3.2	1.6	7.3

Dimension: mm

LOW PROFILE SHIELDED SMD POWER INDUCTORS




10.3 x 10.4 x 4.0 mm

ASPI-104S



RoHS
Compliant

REFLOW PROFILE:

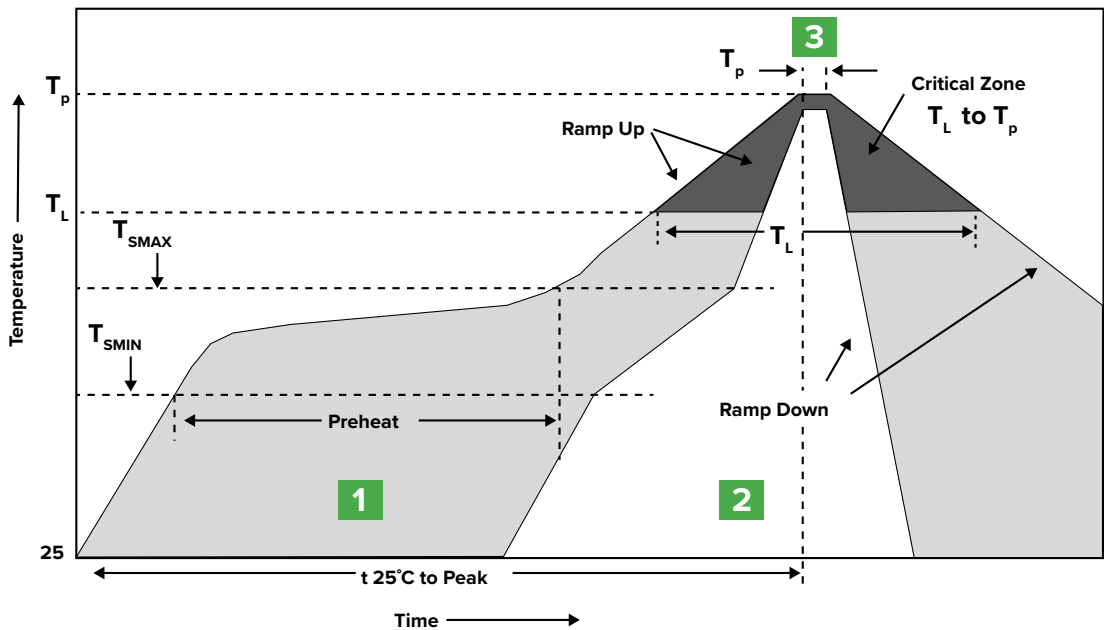

Zone	Description	Temperature	Time
1	Preheat / Soak	$T_{SMIN} \sim T_{SMAX}$ 150°C ~ 180°C	90 ~ 120 sec.
2	Reflow	T_L 200°C	60 sec. MAX
3	Peak heat	T_P 260°C±5°C	10 sec. MAX

LOW PROFILE SHIELDED SMD POWER INDUCTORS

ASPI-104S




RoHS
Compliant



10.3 x 10.4 x 4.0 mm

PACKAGING:

T: 750 pcs / reel

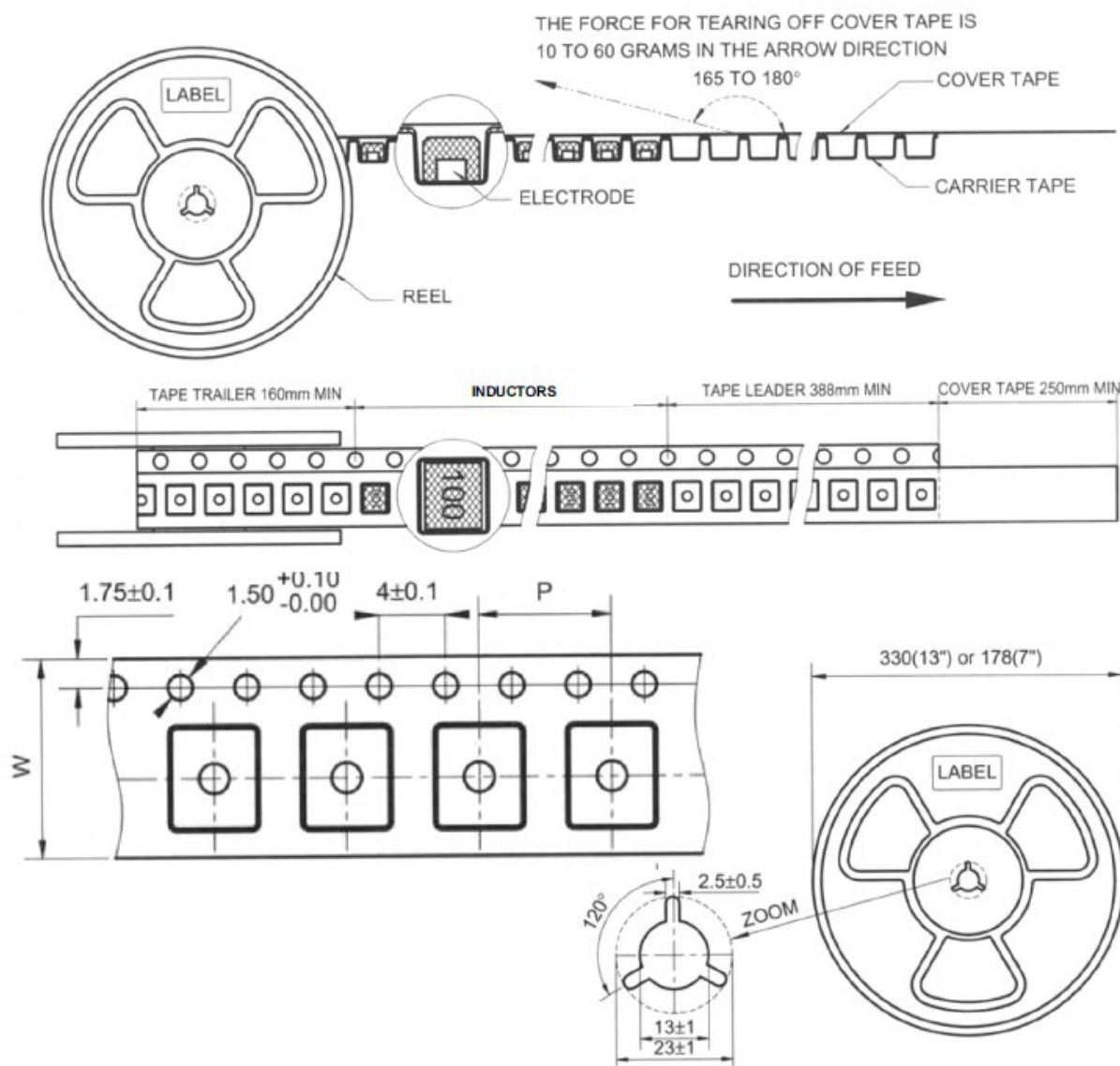

Tape Size		Parts Per Reel
W	P	13''
24	16	750 pcs

Dimension: mm

ATTENTION: Abracon LLC's products are COTS – Commercial-Off-The-Shelf products; suitable for Commercial, Industrial and, where designated, Automotive Applications. Abracon's products are not specifically designed for Military, Aviation, Aerospace, Life-dependent Medical applications or any application requiring high reliability where component failure could result in loss of life and/or property. For applications requiring high reliability and/or presenting an extreme operating environment, written consent and authorization from Abracon LLC is required. Please contact Abracon LLC for more information.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

ABRACON:

[ASPI-104S-100M-T](#) [ASPI-104S-101M-T](#) [ASPI-104S-121M-T](#) [ASPI-104S-150M-T](#) [ASPI-104S-151M-T](#) [ASPI-104S-180M-T](#) [ASPI-104S-181M-T](#) [ASPI-104S-220M-T](#) [ASPI-104S-221M-T](#) [ASPI-104S-270M-T](#) [ASPI-104S-330M-T](#) [ASPI-104S-331M-T](#) [ASPI-104S-470M-T](#) [ASPI-104S-680M-T](#) [ASPI-104S-7R0M-T](#)