


OA172S Series - Salt Fog



AC Fan - 115V, 230V
172 x 150 x 51mm (6.7"x 5.9"x 2")

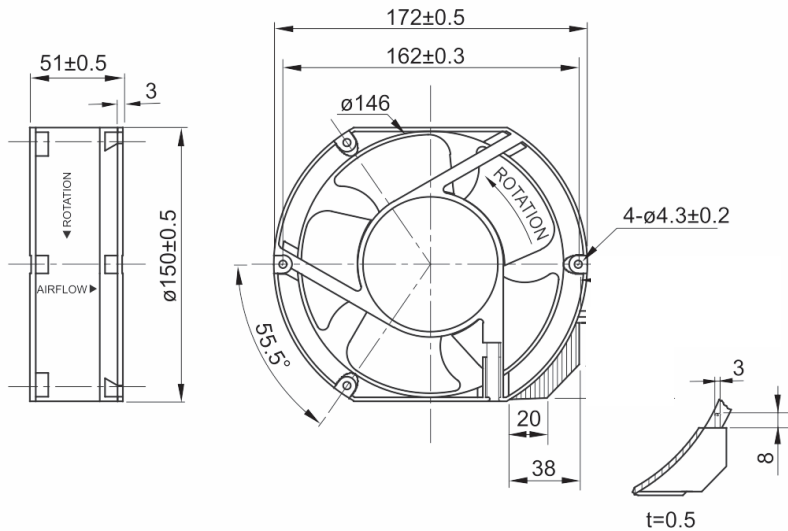

Frame	Diecast Aluminum	Environmental Protection SALT FOG RATED	
Impeller	PBT, UL94V-0 plastic		
Connection	Terminals	Operating Temperature -20C ~ +70C	
Motor	AC Capacitor drive, Thermally protected	Storage Temp -30C ~ +80C	
Bearing System	Dual ball bearing	Life Expectancy >40,000 hours (L10, 40C)	
Insulation Resistance	>100M ohm between lead- wire and frame (500VDC)	Weight: ~ 1.9 lbs m2	
Dielectric Strength	1 min at 1500 VAC,50/60 Hz		

Model Number	OA172SAP-11-1TBSF	OA172SAP-22-1TBSF
Part Number	230315562	230615562
Nominal Voltage	115 VAC	230 VAC
Voltage Range	103 ~ 126 VAC	207 ~ 253 VAC
Rated Current	0.25 A	0.12 A
Locked Current	0.43 A	0.19 A
Rated Power	31 W	29 W
Rated Speed (RPM)	3400	3400
Airflow (CFM)	226	226
Noise Level (dB)	58	58
Max. Static Pressure (\" H ₂ O)	0.79	0.79

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA172SAP-22-1TB\(SF\)](#) [OA172SAP-11-1TB\(SF\)](#)