


70-781T-1 Socket/15 Amp Rating, 300 Volts

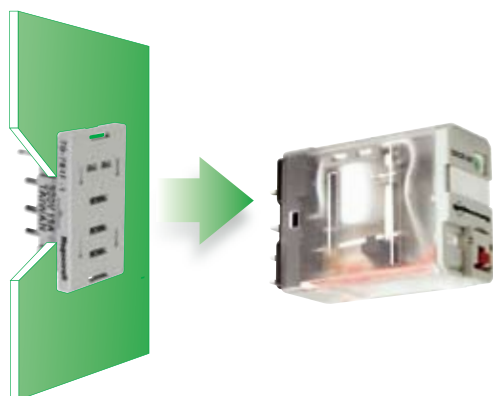

Printed Circuit Board Mounting



BOLD-FACED PART NUMBERS ARE NORMALLY STOCKED

Standard Part Number

Description

70-781T-1

5-Pin, Printed Circuit Terminals


General Specifications (UL 508)

Characteristics	Units	Value
Number of Terminals		5
Electrical Rating		
Nominal Voltage Rating	Volts	300
Nominal Current Rating	Amps	15
Dielectric Strength		
Output to Input Terminals	V rms	2500
Temperature		
Operating Range:	°C	- 40 to + 80
Storage Range:	°C	- 40 to + 105
Construction		
Internal Metal Tracks		Copper Alloy, Tin Plated
Terminals		Copper Alloy, Tin Plated
Miscellaneous		
Socket Mounting:		Printed Circuit
Connection Method		Solder
Flamability Rating	Class	94V-0
Body Color		Light Gray
Product Certification		UL, CSA
Conformance		CE, RoHS
Weight	grams	18

Optional Mating Accessories




781 Relay

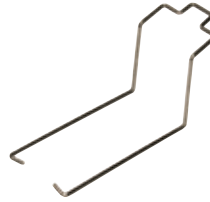

16-781SC

Standard Part Number	Description	Catalog Location
781	Relay	Section 1 p.10-11
16-781SC	Metal Hold-Down Clip	Section 3 p.8-11

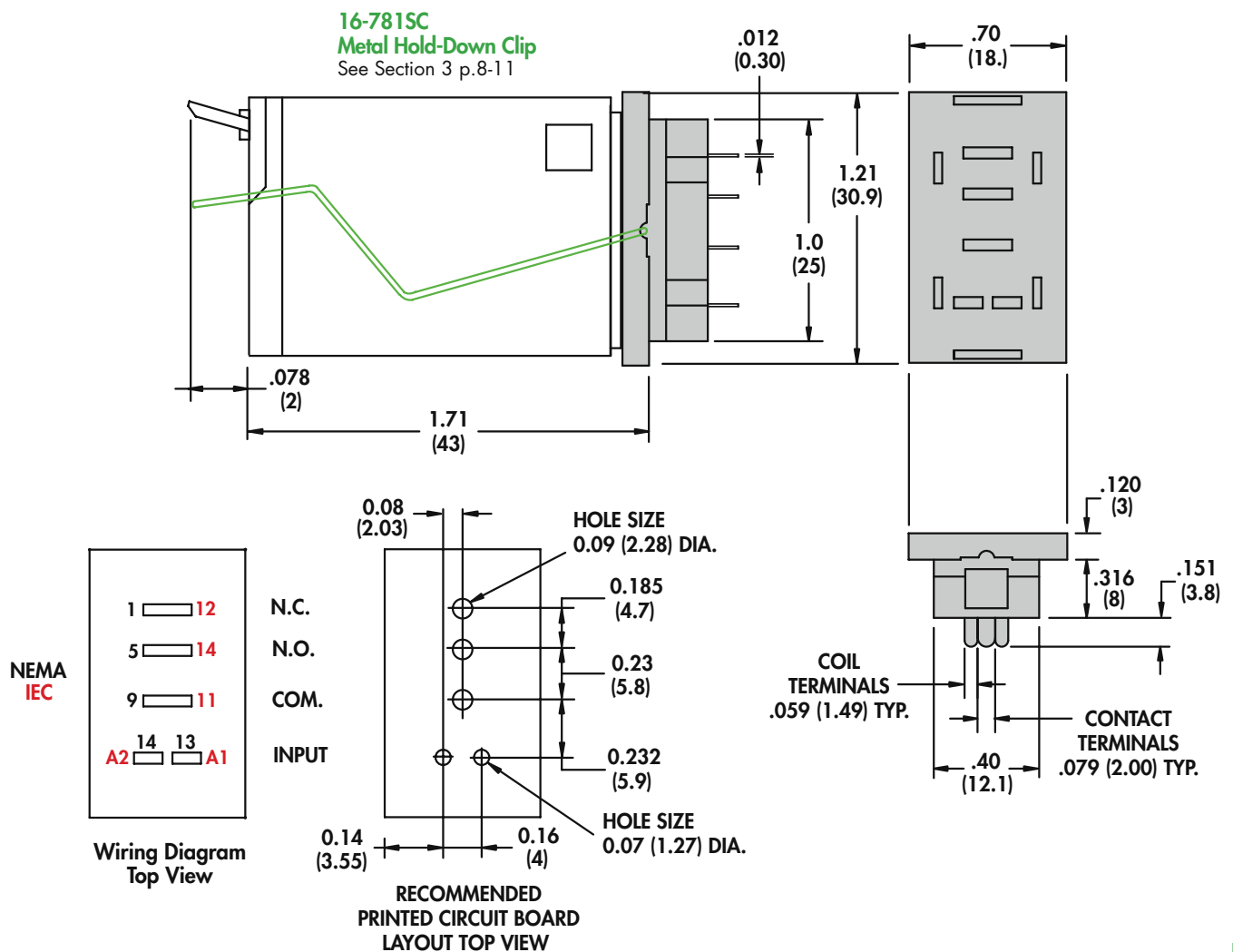

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Schneider Electric:](#)

[70-781T-1](#)