
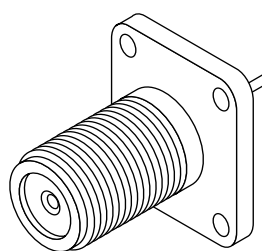
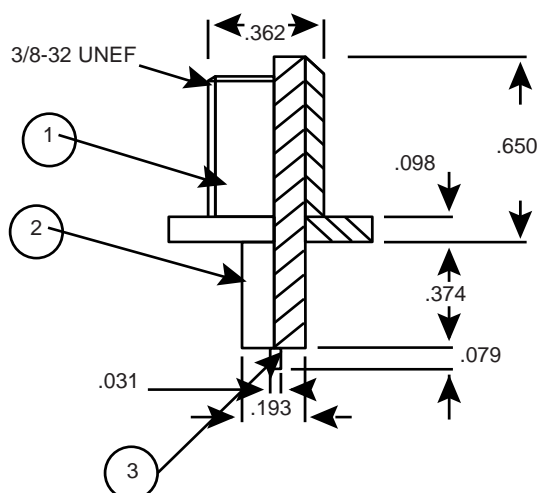


# F Receptacle Jack

161-9126

**KOBI**CONN

F Receptacle Jack

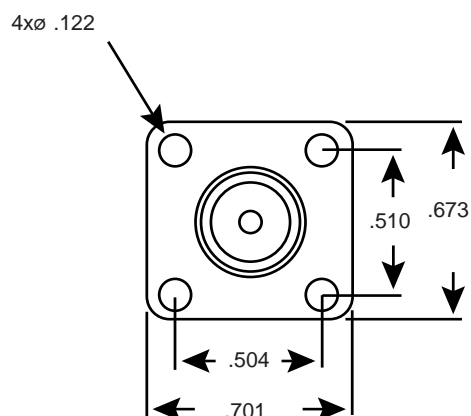

Dimensions: In.

SPECIFICATIONS	
Frequency Range:	0 - 1GHz
Insertion Loss:	0.1 dB max. at 1GHz
Contact Resistance:	5mΩ at DC 1A
Current Rating:	1.5A DC

Materials	
Barrel:	Nickel plated brass
Insulator:	Teflon, white color
Contact:	Gold plated brass

Date Last Revised: 12-20-04

Available from Mouser Electronics  
1-800-346-6873  
www.mouser.com

KC- 300229

161-9126

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[161-9126](#)