


# PLCC Sockets

151-1530, 151-1546, 151-1570, 151-1586



PLCC Sockets

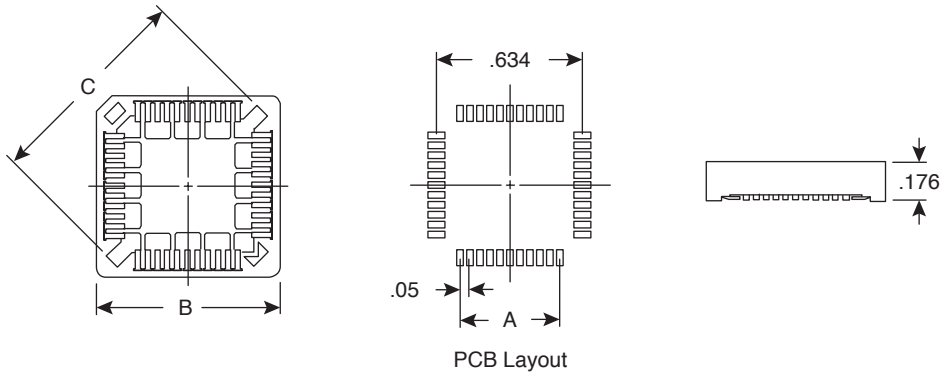

Dimensions: In.

## SPECIFICATIONS

|                        |                      |
|------------------------|----------------------|
| Type:                  | Surface Mount PLCC   |
| Contact Resistance:    | 30mΩ max. @ 100mA DC |
| Insulation Resistance: | 1000MΩ min. @ 500VDC |
| Current Rating:        | 1A                   |
| Voltage Rating:        | 500VAC for 1 Minute  |
| Operating Temperature: | -65°C ~ +125°C       |

## MATERIALS

|              |                            |
|--------------|----------------------------|
| Solder Pads: | .03" x .075"               |
| Contacts:    | Tin Plated Phosphor Bronze |
| Housing:     | PPS & 40% Glass Fiber      |

| MOUSER STOCK NO. | No. of Contacts | Dimensions: In. |      |      |
|------------------|-----------------|-----------------|------|------|
|                  |                 | A               | B    | C    |
| 151-1530         | 28              | .30             | .709 | .771 |
| 151-1546         | 44              | .50             | .928 | 1.09 |
| 151-1570         | 68              | .80             | 1.25 | 1.51 |
| 151-1586         | 84              | 1               | 1.42 | 1.76 |

Date Last Revised: 10-18-05

Available from Mouser Electronics  
1-800-346-6873  
www.mouser.com

KC-300748

151-1530, 151-1546, 151-1570, 151-1586

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[151-1530](#) [151-1570](#) [151-1586](#) [151-1546](#)