


JSM Series Sub-Miniature Slide Switches

Features/Benefits

- RoHS compliant and meets all requirements of RoHS directive 2002/95EC, Halogen Free
- Positive detent
- Low profile
- IR reflow to 260° solder profile
- Surface and thru hole mounting
- Maintained and momentary functions
- SPDT, SP3T models

Typical Applications

- Telecommunication products
- Computer peripherals
- Thermostat select switch
- Instrumentations

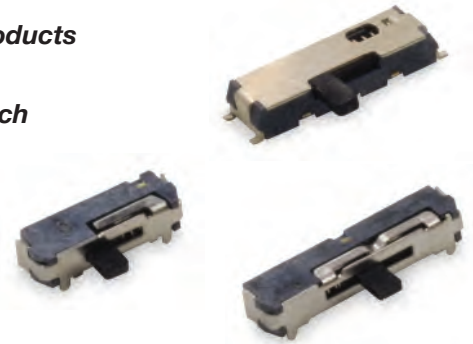


Specifications

CONTACT RATING: 4 VDC @ 0.3A
ELECTRICAL LIFE: 10,000 make-and-break cycles at full load.
CONTACT RESISTANCE: 70 m Ω max.
INSULATION RESISTANCE: 100 M Ω min. @ 500V.
DIELECTRIC STRENGTH: 100 VAC min. @ sea level.
OPERATING TEMPERATURE: -10°C to +60°C
STORAGE TEMPERATURE: -30°C to +85°C


NOTE: Specifications and materials listed above are for switches with standard options.
For information on specific and custom switches, consult Customer Service Center.

Materials

HOUSING: LCP, Glass filled (Halogen free)
ACTUATOR: 4/6 nylon (UL94V-2), black.
CONTACTS: Beryllium copper, silver plated.
TERMINALS: Brass, silver plated.
COVER: Stainless steel
RETURN SPRING: Stainless steel

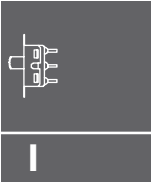


Slide

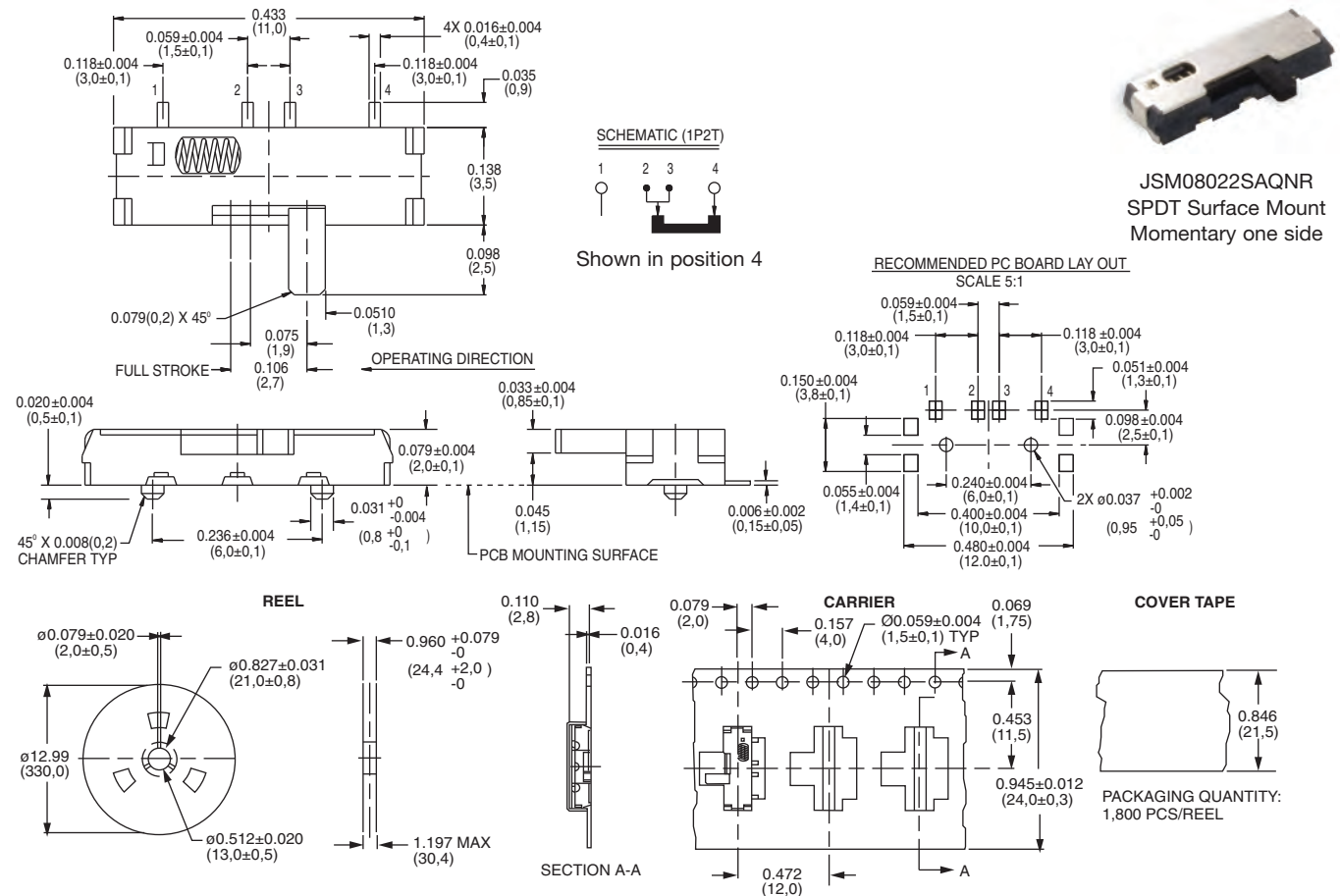

Dimensions are shown: Inches (mm)
Specifications and dimensions subject to change

www.ck-components.com




JSM Series Sub-Miniature Slide Switches

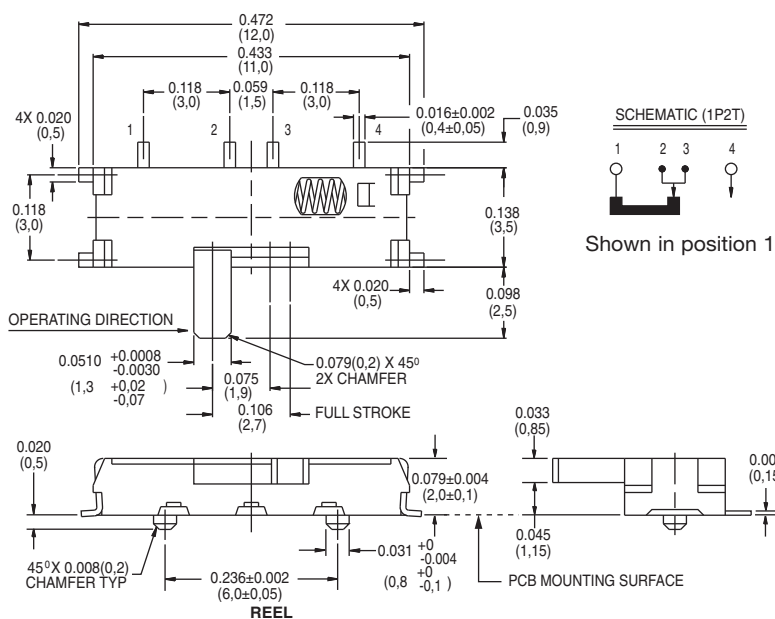

JSM08022SAQNL
SPDT Surface Mount
Momentary only




SCALE 5:1

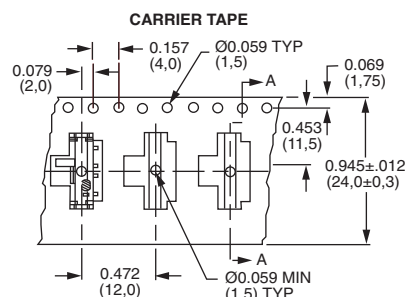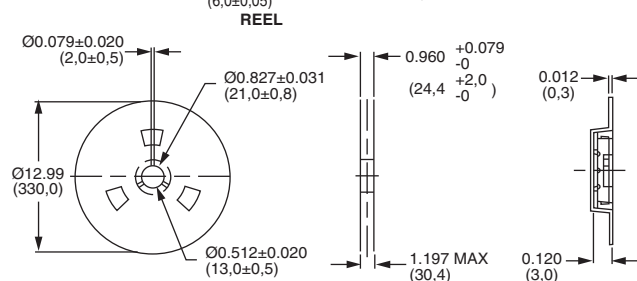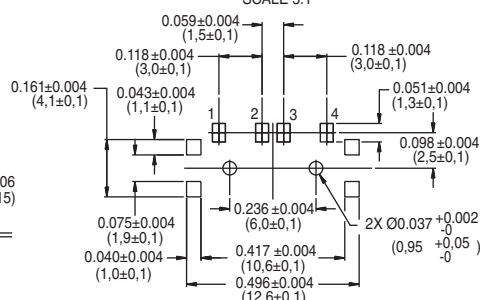




COVER TAPE



PACKAGING QUANTITY:
1.800 PCS/REEL

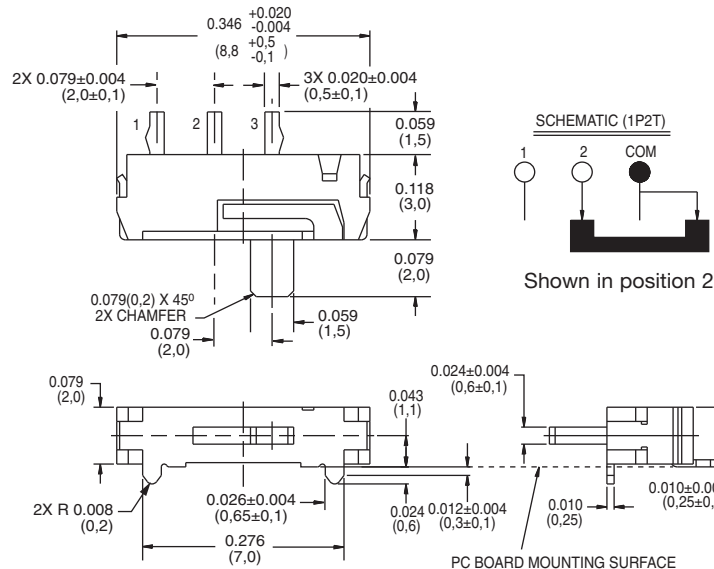


JSM08011SAQNR
SPDT Surface Mount
Momentary only

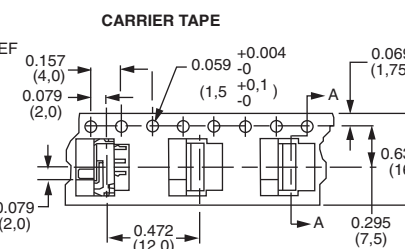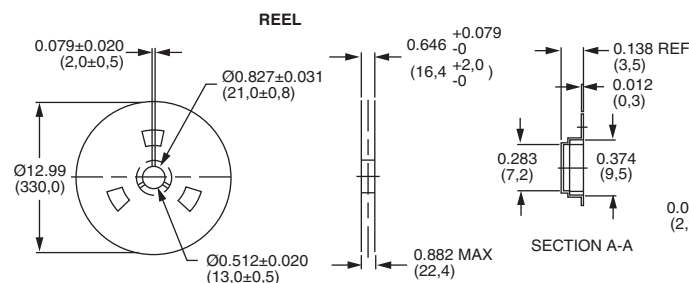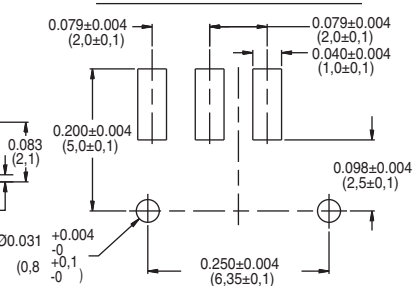

COVER TAPE



 PACKAGING QUANTITY:
1,800 PCS/REEL




Third Angle Projection

Dimensions are shown: Inch (mm)
and dimensions subject to change


JSM Series Sub-Miniature Slide Switches




JSM08011SAQNL
SPDT Surface Mount
Momentary only

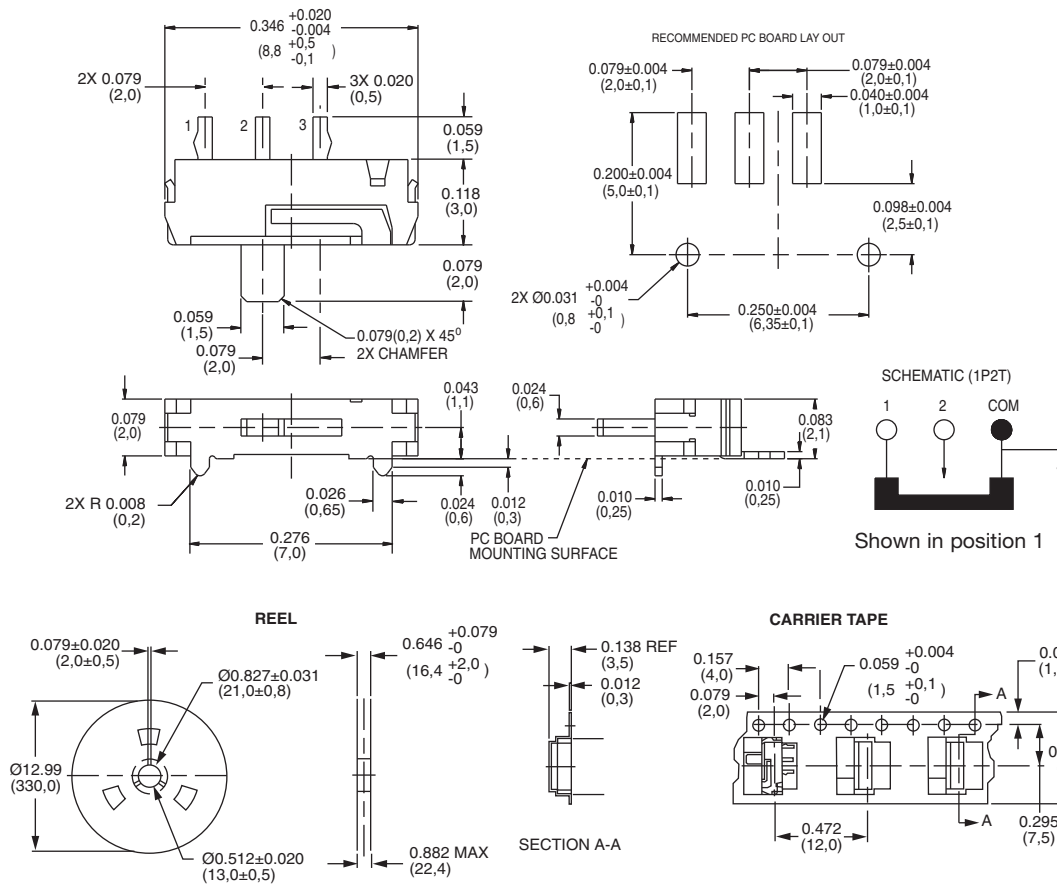


JSM07011SAQNR
SP3T Surface Mount
Momentary one side
& Maintained the other

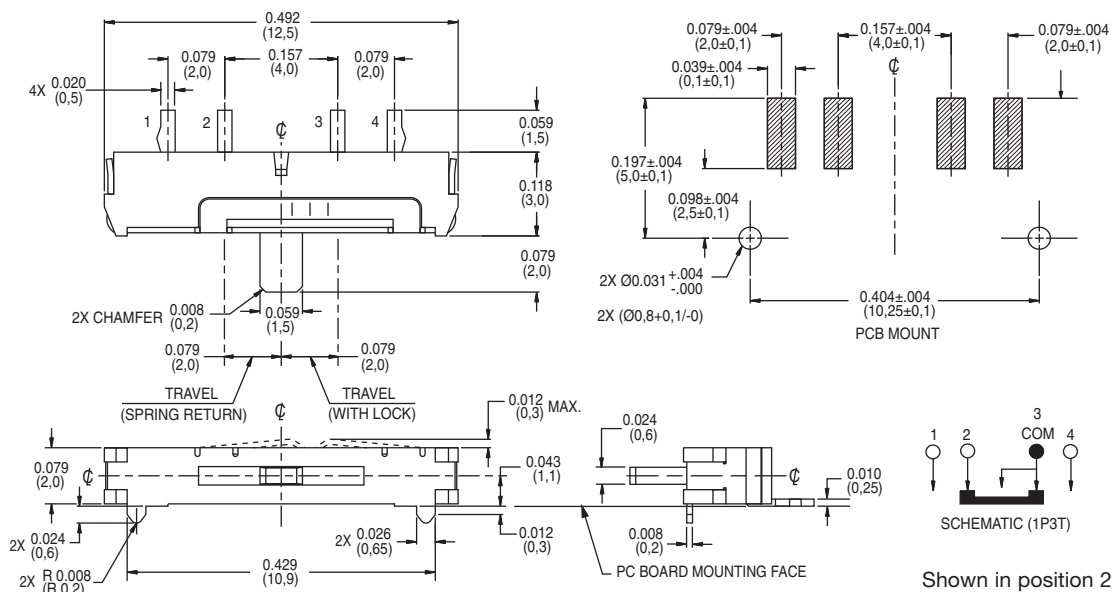

JSM Series Sub-Miniature Slide Switches

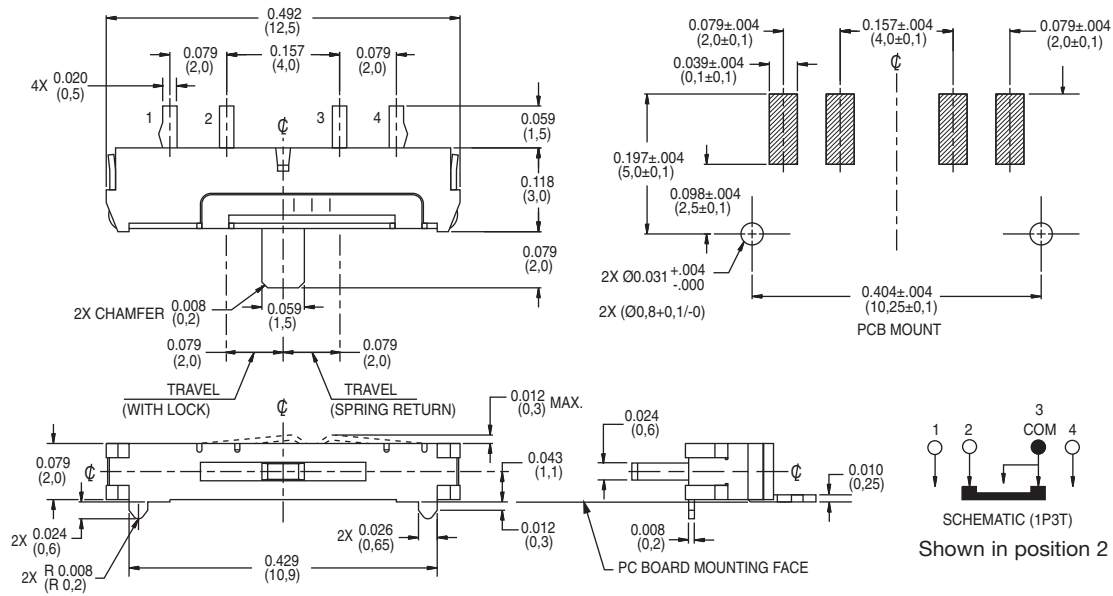



Packaging for JSM07011SAQNR and JSM07011SAQNL

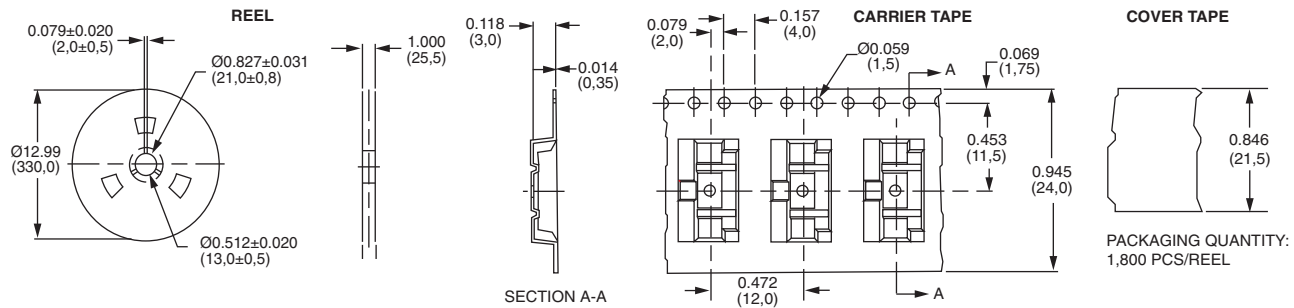





JSM Series Sub-Miniature Slide Switches



JSM05000SAQN
SP3T Surface Mount
Momentary both
sides

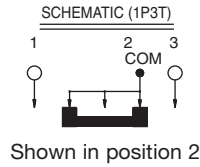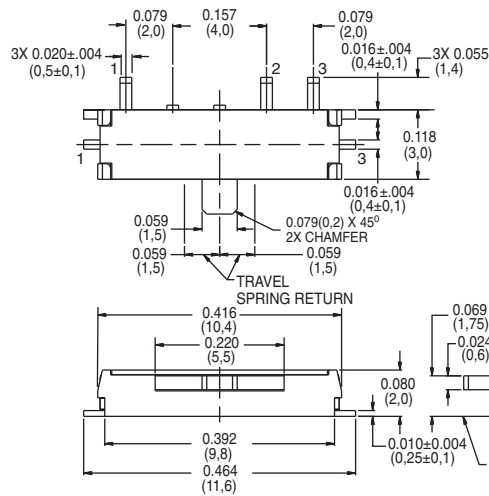

RECOMMENDED PC BOARD LAY OUT
SCALE 5:1

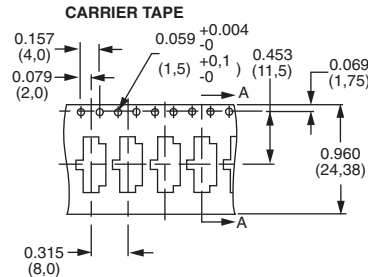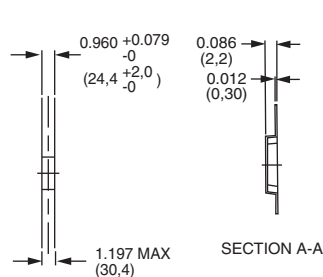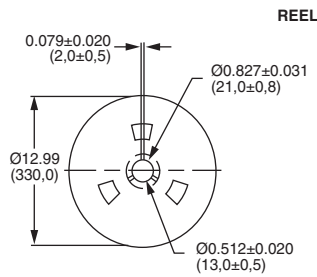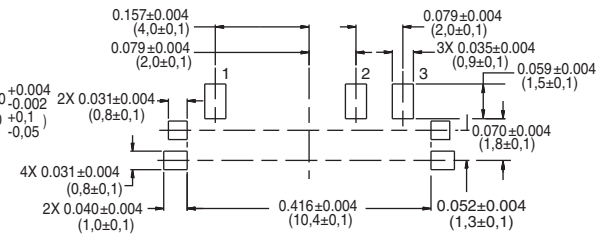

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

C&K Switches:

[JSM07011SAQNL](#) [JSM05000SAQN](#) [JSM07011SAQNR](#) [JSM08011SAQNL](#) [JSM08011SAQNR](#) [JSM08022SAQNL](#)
[JSM08022SAQNR](#)