

PTS635 Series 3,5 mm Tact Switches

Features/Benefits

- Compact size 6 x 3.5 mm
- Variety of switch heights
- Choice of actuation force
- RoHS compliant and compatible

Typical Applications

- Consumer products
- Instrumentation
- Computer products
- Industrial



Specification

FUNCTION: Momentary action
CONTACT ARRANGEMENT: SPST, N.O.
TERMINALS: PC pins

Mechanical

ACTUATION FORCE: PTS635L models: 130 grams.
PTS635H models: 200 grams.
LIFE EXPECTANCY: 20,000 operations.

Electrical

CONTACT RATING: 50 mA @ 12 V DC.
DIELECTRIC STRENGTH: 250 V AC min.
CONTACT RESISTANCE: 100 mΩ max. initial.
INSULATION RESISTANCE: 10¹¹Ω min.

Environmental

OPERATING TEMPERATURE: -40°C to 60°C

NOTE: Specifications listed above are for switches with standard options.
For information on specific and custom switches, consult Customer Service Center.

Process

SOLDERING: Preheating to 100°C for 45 sec. max. Keep flux flush with top surface of PCB; do not apply to component side of PCB and area where terminals are located. Soldering to 255°C for 5 sec. max. Clean by brushing on solder surface. Do not clean switch with solvents.

Materials

BASE: 6/6 nylon or glass filled polyester (PBT) (UL 94V-0).
ACTUATOR: 6/6 nylon or polyacetal (UL 94HB).
COVER PLATE: Tin plated stainless steel
DOME CONTACTS: Phosphor bronze, silver clad.
STATIONARY CONTACTS: Brass, silver plated.
TERMINALS: Brass, silver plated. Insert molded.


Packaging

Bulk packaging.

Tape & reel for:
PTS635Sx43SMTR, 1700 pcs per reel

How To Order


Our easy build-a-switch concept allows you to mix and match options to create the switch you need. To order, select desired option from each category and place it in the appropriate box.

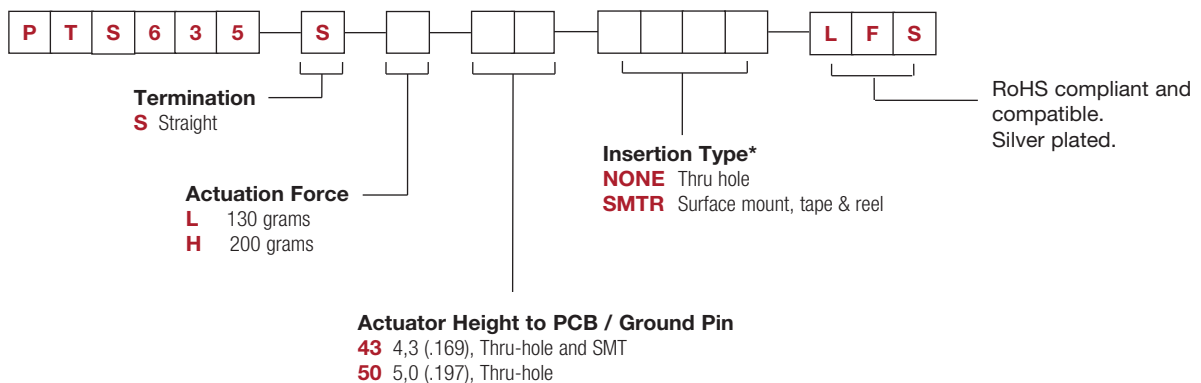

* SMTR only available with PTS635 43 Actuator Height options.


PTS635 Series 3,5 mm Tact Switches

THRU-HOLE

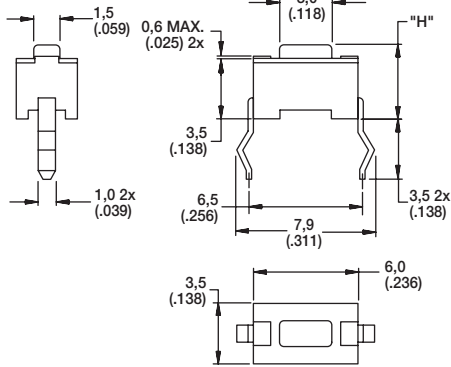


For "H" dimension please refer to chart on next page

 
PCB LAYOUT



SMT

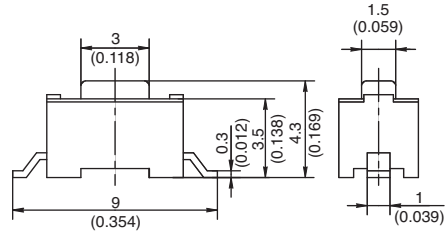


PCB LAYOUT

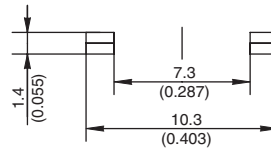

ACTUATION FORCE


OPTION CODE	FORCE
L	130 grams
H	200 grams

 ACTUATOR HEIGHT

OPTION CODE	HEIGHT "H" or LENGTH "L"	TERMINATION	SCHEMATIC
43	4,3 (.169)	Thru-hole & SMT	1  2
50	5,0 (.197)	Thru-hole	

INSERTION TYPE

SMTR 43

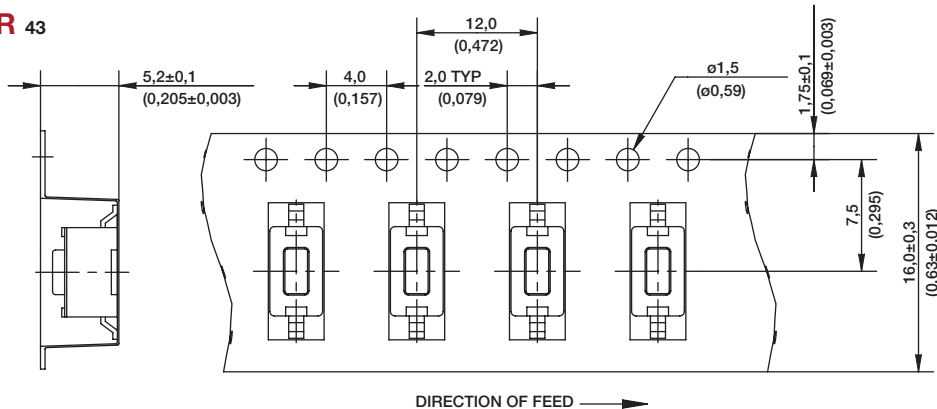

Dimensions are shown: mm
Specifications and dimensions subject to change

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

C&K Switches:

[PTS635SL43](#) [PTS635SL50](#) [PTS635VH39](#) [PTS635VL39 LFS](#) [PTS635SL25SMTR LFS](#) [PTS635SK25SMTR LFS](#)
[PTS635VH39 LFS](#) [PTS635VH31 LFS](#) [PTS635VL31 LFS](#) [PTS635SL43 LFS](#) [PTS635SL43SMTR LFS](#) [PTS635SH43](#)
[LFS](#) [PTS635SL50 LFS](#) [PTS635SH50LFS](#) [PTS635SH43SMTRLFS](#) [PTS635SK43SMTRLFS](#) [PTS635SL50LFS](#)
[PTS635SH43LFS](#) [PTS635SL43SMTRLFS](#) [PTS635SL43LFS](#)