

Tip Plug

Insulated Standard: Small Handle (Solder or Crimp)



INCHES (MILLIMETERS)
CUSTOMER DRAWINGS AVAILABLE UPON REQUEST

SPECIFICATIONS

Contact: Brass per QQ-B-626D

Finish: Nickel


Insulated Handle: Nylon 6/6 per ASTM D4066

RATINGS

Current: 10 amps

Breakdown Voltage: 3500 Vrms minimum

Contact Resistance: 0.010 ohms maximum

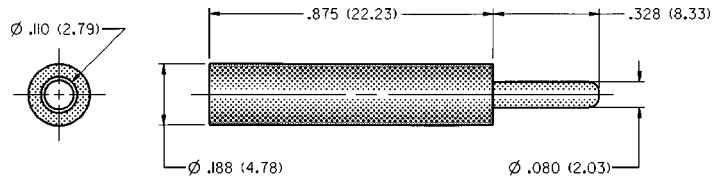


NICKEL PLATING	
SOLDER TYPE UP TO 16 GAUGE	CRIMP TYPE 16 GAUGE
PART NO.	COLOR
105-0771-001	White

For Standard Tip Jack: .080 (2.00) Diameter

FEATURES:

 - Solder or crimp type connection
- Accepts wire sizes up to 16 gauge
- Nylon UL approved for self extinguishing



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cinch Connectivity Solutions:](#)

[105-0771-001](#)