

6 DIGIT MICRO COUNTER

Issue 4.2018

6mm DIGIT HEIGHT



Outline dimensions: 28x18x6.5mm




with bezel EA 021


FEATURES

- * LCD 6 DIGIT (MULTIPLEX)
- * 6mm DIGIT HEIGHT
- * POWER SUPPLY 2.6V TO 3.4V / TYP. 5 μ A (QUIESCENT CURRENT)
- * MAX. INPUT 10KHz
- * COUNTING AT FALLING EDGE, PULSE WIDTH MIN. 50 μ s
- * THRESHOLD 0.7V
- * RESET INPUT AT LOW, PULS WIDTH MIN. 15ms
- * CLEAR POLYCARBONATE CASE IP40
- * OPERATING TEMPERATURE RANGE -10 TO +60 °C
- * STORAGE TEMPERATURE RANGE -10 TO +60 °C
- * CONNECTION: 5 PINS (2.54mm PITCH), 1 CENTER PIN (DO NOT CONNECT)
- * ACCESSORY: SNAP-IN BEZEL **EA 021**, CUTOUT 29.4x22mm


DIMENSION

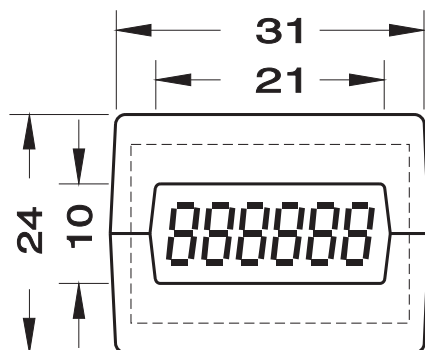

mit Rahmen EA 021

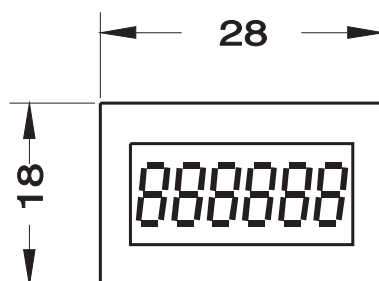

ohne Rahmen

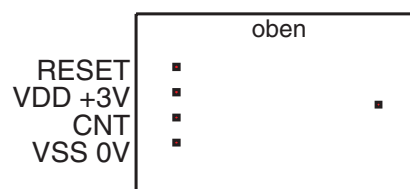

Ansicht von hinten

ORDERING INFORMATION

MICRO COUNTER, 6 DIGIT, INCL. SNAP-IN CASE
SNAP-IN BEZEL, 2 PARTS

EA 2021-N
EA 021

6 DIGIT UP/DOWN LCD COUNTER



Outline dimensions: 28x18x6.5mm




with bezel EA 021


FEATURES

- * LCD 6 DIGIT (MULTIPLEX)
- * 6mm DIGIT HEIGHT
- * POWER SUPPLY 2.6V TO 3.4V / TYP. 5µA (QUIESCENT CURRENT)
- * MAX. INPUT 10KHz
- * COUNTING AT FALLING EDGE, PULSE WIDTH MIN. 50µs
- * THRESHOLD 0.7V
- * RESET INPUT AT LOW, PULS WIDTH MIN. 15ms
- * CLEAR POLYCARBONATE CASE IP40
- * OPERATING TEMPERATURE RANGE -10 TO +60 °C
- * STORAGE TEMPERATURE RANGE -10 TO +60 °C
- * CONNECTION: 5 PINS (2.54mm PITCH)
- * DIRECTION PIN HIGH: UP-COUNTING, LOW: DOWN-COUNTING
- * ACCESSORY: SNAP-IN BEZEL **EA 021**, CUTOUT 29.4x22mm

DIMENSION

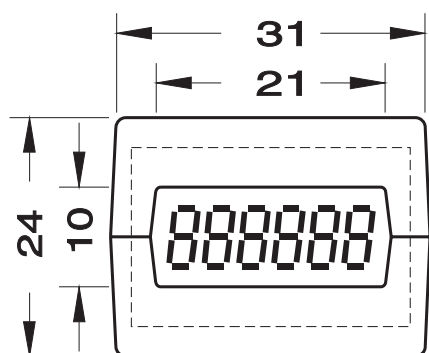

mit Rahmen EA 021

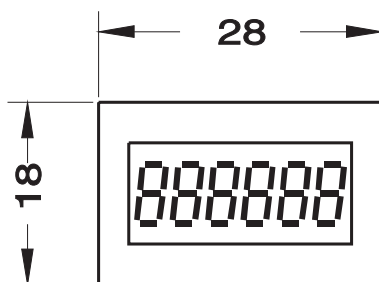

ohne Rahmen



Ansicht von hinten

ORDERING INFORMATION

UP/DOWN COUNTER, 6 DIGIT, LCD, INCL. SNAP-IN BEZEL
SNAP-IN BEZEL, 2 PARTS

EA 2022-N
EA 021

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Display Visions:](#)

[EA 2022-N](#)