

PRODUCT NUMBER

76342-YXXXLF

RoHS COMPATIBLE, SEE NOTE 5

OPTIONAL LETTER

H: HIGH TEMPERATURE PRODUCT.

C: PACKAGED IN SHORT TUBE.

NUMBER OF POSITIONS PER ROW: 02 TO 50.




PLATING CODE

3= 0.76µm GOLD ON CONTACT AREA.

2µm MIN MATTE TIN ON TAIL.

4= 2µm MIN MATTE TIN FULL PLATED

1.27µm Ni MIN UNDERPLATING

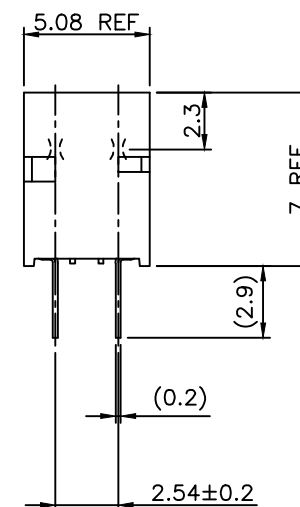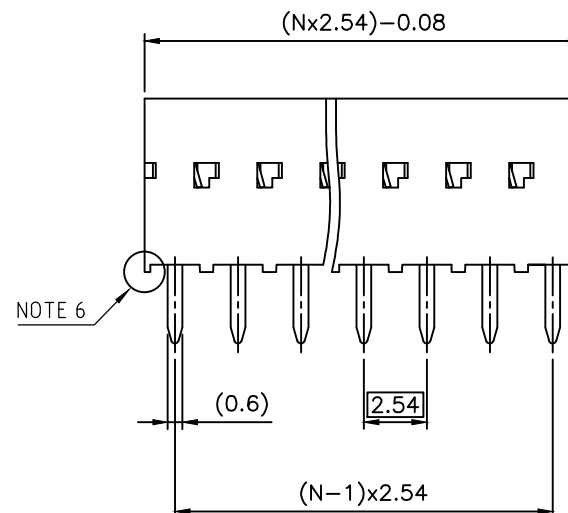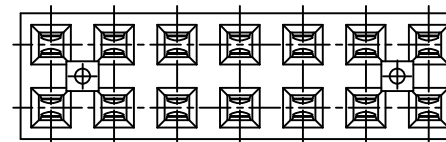

NOTES:

- 1 - HOUSING MAT'L: THERMOPLASTIC GLASS FILLED
FLAME RETARDANT PER UL 94 V-0
LOW TEMPERATURE: COLOR BLUE
HIGH TEMPERATURE: COLOR GREY.
- 2 - TERMINAL MATERIAL: PHOSPHOR BRONZE.
- 3 - 2 UP TO 4 POSITIONS PRODUCT PACKED IN PLASTIC BOX.
5 UP TO 50 POSITIONS PRODUCT PACKED IN TUBE.
- 4 - TO DETERMINE DIMENSIONS:
N = NUMBER OF POSITIONS PER ROW
EXAMPLE: 8 POS: $(N \times 2.54) - 0.08 = 20.24$ mm
- 5 - RoHS COMPATIBLE PRODUCT SPECIFICATIONS
 - a - PLATING:
 - "LF" MEANS THE PRODUCT IS LEAD-FREE,
2µm MINIMUM MATTE TIN OVER 1.27µm
MINIMUM NICKEL UNDERPLATE.
 - b - MANUFACTURING PROCESS COMPATIBILITY
 - THE HOUSING WILL WITHSTAND EXPOSURE TO
260°C ± 5°C SOLDER BATH TEMPERATURE FOR
5 SECONDS IN A WAVE SOLDER APPLICATION
WITH A 1.6mm MIN THICK CIRCUIT BOARD.
 - c - LABELING:
 - MEETS PACKAGING SPECS AS PER GS-14-920
 - d - LEGAL STATEMENT: SEE GS-47-0004
- 6 - END STAND-OFFS FOR 2x2 UP TO 2x5 POS
NO END STAND-OFFS FOR 2x6 UP TO 2x50 POS

mat'l. code SEE NOTES 1 & 2				surface ISO 1302	tolerance ISO 406 ISO 1101	projection mm	product family DUBOX			
ltr	ecr no	dr	date	tolerances unless otherwise specified		mm	title BtB RECEPT. VERT DR TMT			
S	F10342	DLE	01.06.12	angles	linear					
T	F04-0347	DLE	04.09.27	±2°		scale 5:1	dwg no 76342			
U	F06-0137	DLE	06.02.27							
V	F06-0204	DLE	06.06.20	dr	D LEGRAND	04.09.27	sheet 1 of 2 size A3			
W	F11-0043	JCO	12.02.22	enrg	P NIZZI	04.09.27				
X	B-19123	LMU	14.10.21	chr	D LEGRAND	04.09.27	type CUSTOMER Drawing			
Y	B-21211	AMA	15.06.22	appd	P NZ	04.09.27				
sheet	revision	Y	C							
index	sheet	1	2							

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

FCI:

[76342-307HLF](#) [76342-310HLF](#) [76342-313HLF](#) [76342-405HLF](#) [76342-302HLF](#) [76342-306HLF](#) [76342-308HLF](#)
[76342-315HLF](#) [76342-324CLF](#) [76342-324H](#) [76342-324HLF](#) [76342-330SLF](#) [76342-303HLF](#) [76342-325HLF](#) [76342-424HLF](#)
[76342-305HLF](#) [76342-320HLF](#) [76342-309HLF](#) [76342-318HLF](#) [76342-304HLF](#) [76342-410HLF](#)