

Heyco® Thick Panel Rubber Grommets

For Panels .250" (6,4 mm) to .375" (9,5 mm) Thick


MOUNTING HOLE DIAMETER		PART NO. Black	DESCRIPTION	PART DIMENSIONS					
in.	mm.			A Inside Diameter		B Head Diameter		C Overall Height	
				in.	mm.	in.	mm.	in.	mm.
For .250" (6,4 mm) Thick Panels									
.312	7,9	G1023	RG 312-6-8	.188	4,8	.437	11,1	.375	9,5
.437	11,1	G1058*	RG 437-8-8	.250	6,4	.625	15,9		
.500	12,7	G1086*	RG 500-10-8	.313	8,0	.625	15,9	.625	15,9
		G1095	RG 500-12-8	.375	9,5	.750	19,1	.500	12,7
.562	14,3	G1117*	RG 562-10-8	.313	8,0	.812	20,6		
.625	15,9	G1134	RG 625-12-8	.375	9,5	.875	22,2	.500	12,7
.687	17,5	G1154	RG 687-14-8	.438	11,1	.937	23,8		
.812	20,6	G1195	RG 812-16-8	.500	12,7	1.062	27,0	.500	12,7
		G1200	RG 812-18-8	.562	14,3				
.875	22,2	G1220	RG 875-20-8	.625	15,9	1.125	28,6	.500	12,7
1.000	25,4	G1257	RG 1000-22-8	.687	17,5	1.312	33,3	.562	14,3
		G1264	RG 1000-28-8	.875	22,2	1.250	31,8	.625	15,9
1.062	27,0	G1273	RG 1062-24-8	.750	19,1	1.375	34,9	.562	14,3
1.250	31,8	G1301	RG 1250-24-8	.750	19,1	1.625	41,3	.438	11,1
		G1307	RG 1250-28-8	.875	22,2	1.625	41,3	.625	15,9
1.375	34,9	G1324	RG 1375-32-8	1.000	25,4	1.750	44,5	.625	15,9
1.500	38,1	G1353	RG 1500-40-8	1.250	31,8	1.750	44,5	.500	12,7
		G1354	RG 1500-40-8A	1.250	31,8	2.000	50,8	.516	13,1
1.750	44,5	G1373	RG 1750-48-8	1.500	38,1	2.000	50,8	.500	12,7
		G1374	RG 1750-48-8A	1.500	38,1	2.125	54,0	.625	15,9
2.000	50,8	G1393	RG 2000-56-8	1.750	44,5	2.500	63,5	.531	13,5
		G1394*	RG 2000-56-8A	1.750	44,5	2.500	63,5	.560	14,2
2.500	63,5	G1421	RG 2.5-64-8	2.000	50,8	3.000	76,2	.562	14,3
		G1425	RG 2.5-72-8	2.250	57,2	3.000	76,2	.625	15,9

For .375" (9,5 mm) Thick Panels									
.375	9,5	G1043	RG 375-10-12	.313	8,0	.562	14,3	.500	12,7
.500	12,7	G1096	RG 500-12-12	.375	9,5	.625	15,9	.625	15,9
.562	14,3	G1121	RG 562-12-12	.375	9,5	.750	19,1	.750	19,1
.625	15,9	G1136	RG 625-13-12	.406	10,3	.812	20,6		
.750	19,1	G1182	RG 750-16-12	.500	12,7	1.000	25,4		
.875	22,2	G1214	RG 875-18-12	.562	14,3	1.062	27,0	.625	15,9
1.000	25,4	G1249	RG 1000-18-12	.562	14,3	1.250	31,8		
1.125	28,6	G1278	RG 1125-24-12	.750	19,1	1.625	41,3	1.125	28,6
1.250	31,8	G1308**	RG 1250-28-12	.875	22,2	1.750	44,5	.750	19,1
		G1314	RG 1250-32-12	1.000	25,4	1.500	38,1	.625	15,9
1.375	34,9	G1326	RG 1375-32-12	1.000	25,4	1.750	44,5	.750	19,1
1.750	44,5	G1375	RG 1750-48-12	1.500	38,1	2.125	54,0		
2.000	50,8	G1395	RG 2000-56-12	1.750	44,5	2.500	63,5	.625	15,9
2.500	63,5	G1427	RG 2.5-72-12	2.250	57,2	3.000	76,2	.750	19,1

Standard color black. *Nitrile **Neoprene



- Used to protect through holes. Help eliminate sharp edges so your wires are protected and add aesthetic value to your application.
- 38 sizes available that accommodate mounting holes ranging from .312" (7,9 mm) to holes as large as 2.50" (63,5 mm) in diameter and panel thicknesses of .250" (6,4 mm) and .375" (9,5 mm).
- Rubber grommets are constructed of SBR (unless otherwise noted) with an operating temperature range of -40°F (-40°C) to 221°F (105°C).
- SBR grommets have good water resistant characteristics and are suitable for most moderate chemicals and wet or dry organic acids.
- Provides vibration dampening.

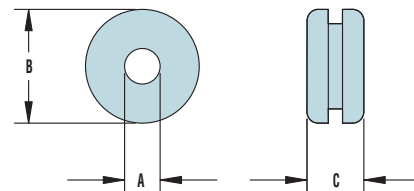

Material SBR (Styrene Butadiene)
Temperature Rating -40°F (-40°C) to 221°F (105°C)

Quick Specs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[G1023](#) [G1278](#) [G1257](#) [G1195](#) [G1395](#) [G1134](#) [G1394](#) [G1273](#) [G1393](#) [G1136](#) [G1117](#) [G1043](#) [G1154](#) [G1421](#)
[G1214](#) [G1220](#) [G1308](#) [G1324](#) [G1264](#) [G1374](#) [G1307](#) [G1427](#) [G1425](#) [G1314](#) [G1200](#) [G1301](#) [G1375](#) [G1354](#)
[G1086](#) [G1096](#) [G1121](#) [G1182](#) [G1095](#) [G1353](#) [G1058](#) [G1326](#) [G1249](#) [G1373](#)