




# Heyco® Nylon PCB Supports - Imperial Spacing

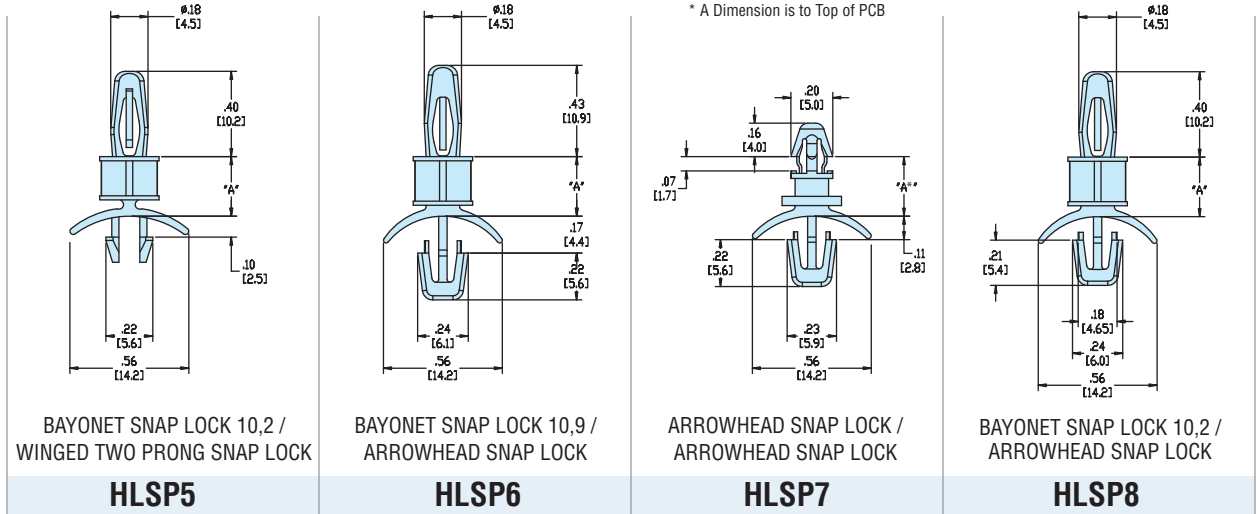

	Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
<b>PCB</b>	.062	1,6	.157	4,0	.090	2,3	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0
<b>Chassis</b>	.078	2,0	.187	4,8	.141	3,6	.187	4,8	.078	2,0	.187	4,8	.055	1,4	.187	4,8

A	PART NO.	DESCRIPTION	PART NO.	DESCRIPTION	PART NO.	DESCRIPTION	PART NO.	DESCRIPTION	
									in.
.187	4,8	<b>10104</b>	HLSP5-03	<b>10118</b>	HLSP6-03	<b>10132</b>	HLSP7-03	<b>10146</b>	HLSP8-03
.250	6,4	<b>10105</b>	HLSP5-04	<b>10119</b>	HLSP6-04	<b>10133</b>	HLSP7-04	<b>10147</b>	HLSP8-04
.312	7,9	<b>10106</b>	HLSP5-05	<b>10120</b>	HLSP6-05	<b>10134</b>	HLSP7-05	<b>10148</b>	HLSP8-05
.375	9,5	<b>10107</b>	HLSP5-06	<b>10121</b>	HLSP6-06	<b>10135</b>	HLSP7-06	<b>10149</b>	HLSP8-06
.437	11,1	<b>10108</b>	HLSP5-07	<b>10122</b>	HLSP6-07	<b>10136</b>	HLSP7-07	<b>10150</b>	HLSP8-07
.500	12,7	<b>10109</b>	HLSP5-08	<b>10123</b>	HLSP6-08	<b>10137</b>	HLSP7-08	<b>10151</b>	HLSP8-08
.625	15,9	<b>10110</b>	HLSP5-10	<b>10124</b>	HLSP6-10	<b>10138</b>	HLSP7-10	<b>10152</b>	HLSP8-10
.750	19,1	<b>10111</b>	HLSP5-12	<b>10125</b>	HLSP6-12	<b>10139</b>	HLSP7-12	<b>10153</b>	HLSP8-12
.875	22,2	<b>10112</b>	HLSP5-14	<b>10126</b>	HLSP6-14	<b>10140</b>	HLSP7-14	<b>10154</b>	HLSP8-14
1.000	25,4	<b>10113</b>	HLSP5-16	<b>10127</b>	HLSP6-16	<b>10141</b>	HLSP7-16	<b>10155</b>	HLSP8-16
1.125	28,6	<b>10114</b>	HLSP5-18	<b>10128</b>	HLSP6-18	<b>10142</b>	HLSP7-18	<b>10156</b>	HLSP8-18
1.250	31,8	<b>10115</b>	HLSP5-20	<b>10129</b>	HLSP6-20	<b>10143</b>	HLSP7-20	<b>10157</b>	HLSP8-20
1.375	34,9	<b>10116</b>	HLSP5-22	<b>10130</b>	HLSP6-22	<b>10144</b>	HLSP7-22	<b>10158</b>	HLSP8-22

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix “F” to Part No.

\*Consult Heyco for HLSP5 & HLSP6 in V-0 material.



Quick Specs

Material: Nylon 6/6  
 Flammability Rating: 94V-2  
 Temperature Range: .4°F (-18°C) to 185°F (85°C)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10142F](#) [10140F](#) [10141F](#) [10138F](#) [10150F](#) [10136F](#) [10148F](#) [10135F](#) [10147F](#) [10153F](#) [10149F](#) [10156F](#) [10152F](#)  
[10132F](#) [10146F](#) [10133F](#) [10158F](#) [10151F](#) [10134F](#) [10139F](#) [10155F](#) [10154F](#) [10143F](#) [10137F](#) [10157F](#) [10144F](#)