



Heyco® Nylon PCB Supports - Metric Spacing

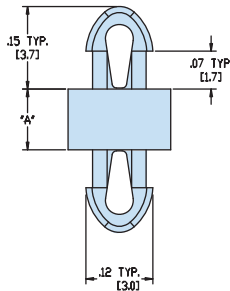


TEARDROP SNAP LOCK /
TEARDROP SNAP LOCK

HSP-MDL-1

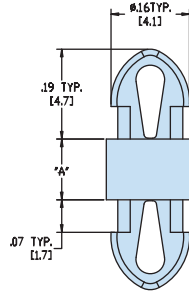


TEARDROP SNAP LOCK /
TEARDROP SNAP LOCK

HSP-MDL-2

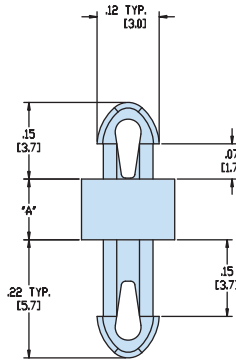

TEARDROP SNAP LOCK /
TEARDROP SNAP LOCK

HSP-MDLS-1

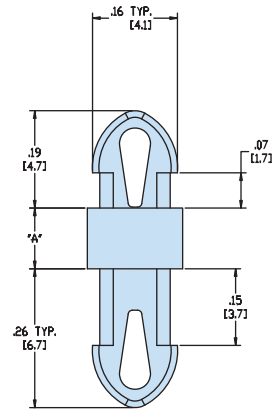

TEARDROP SNAP LOCK /
TEARDROP SNAP LOCK

HSP-MDLS-2

	Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB	.062	1,6	.098	2,5	.062	1,6	.137	3,5	.062	1,6	.098	2,5	.062	1,6	.137	3,5
Chassis	.062	1,6	.098	2,5	.062	1,6	.137	3,5	.141	3,6	.098	2,5	.141	3,6	.137	3,5
A mm.	PART NO. Natural		DESCRIPTION		PART NO. Natural		DESCRIPTION		PART NO. Natural		DESCRIPTION		PART NO. Natural		DESCRIPTION	
2,0	10444		HSP-MDL-1-02M		10461		HSP-MDL-2-02M		10478		HSP-MDLS-1-02M		10493		HSP-MDLS-2-02M	
3,0	10445		HSP-MDL-1-03M		10462		HSP-MDL-2-03M		10479		HSP-MDLS-1-03M		10494		HSP-MDLS-2-03M	
4,0	10446		HSP-MDL-1-04M		10463		HSP-MDL-2-04M		10480		HSP-MDLS-1-04M		10495		HSP-MDLS-2-04M	
5,0	10447		HSP-MDL-1-05M		10464		HSP-MDL-2-05M		10481		HSP-MDLS-1-05M		10496		HSP-MDLS-2-05M	
6,0	10448		HSP-MDL-1-06M		10465		HSP-MDL-2-06M		10482		HSP-MDLS-1-06M		10497		HSP-MDLS-2-06M	
7,0	10449		HSP-MDL-1-07M		10466		HSP-MDL-2-07M		10483		HSP-MDLS-1-07M		10498		HSP-MDLS-2-07M	
8,0	10450		HSP-MDL-1-08M		10467		HSP-MDL-2-08M		10484		HSP-MDLS-1-08M		10499		HSP-MDLS-2-08M	
9,0	10451		HSP-MDL-1-09M		10468		HSP-MDL-2-09M		10485		HSP-MDLS-1-10M		10500		HSP-MDLS-2-10M	
10,0	10452		HSP-MDL-1-10M		10469		HSP-MDL-2-10M		10485		HSP-MDLS-1-10M		10500		HSP-MDLS-2-10M	
12,0	10453		HSP-MDL-1-12M		10470		HSP-MDL-2-12M		10486		HSP-MDLS-1-12M		10501		HSP-MDLS-2-12M	
14,0	10454		HSP-MDL-1-14M		10471		HSP-MDL-2-14M		10487		HSP-MDLS-1-14M		10502		HSP-MDLS-2-14M	
16,0	10455		HSP-MDL-1-16M		10472		HSP-MDL-2-16M		10488		HSP-MDLS-1-16M		10503		HSP-MDLS-2-16M	
18,0	10456		HSP-MDL-1-18M		10473		HSP-MDL-2-18M		10489		HSP-MDLS-1-18M		10504		HSP-MDLS-2-18M	
20,0	10457		HSP-MDL-1-20M		10474		HSP-MDL-2-20M		10490		HSP-MDLS-1-20M		10505		HSP-MDLS-2-20M	
22,0	10458		HSP-MDL-1-22M		10475		HSP-MDL-2-22M		10491		HSP-MDLS-1-22M		10506		HSP-MDLS-2-22M	
26,5	10459		HSP-MDL-1-26.5M		10476		HSP-MDL-2-26.5M									

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

*Quick
Specs*

Material Nylon 6/6
Flammability Rating 94V-2
Temperature Range -40°F (-40°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

<u>10449</u>	<u>10479</u>	<u>10494</u>	<u>10445</u>	<u>10444</u>	<u>10493</u>	<u>10447</u>	<u>10462</u>	<u>10466</u>	<u>10500</u>	<u>10495</u>	<u>10457</u>	<u>10453</u>	<u>10455</u>	<u>10474</u>
<u>10452</u>	<u>10480</u>	<u>10496</u>	<u>10463</u>	<u>10461</u>	<u>10488</u>	<u>10458</u>	<u>10475</u>	<u>10497</u>	<u>10469</u>	<u>10481</u>	<u>10448</u>	<u>10464</u>	<u>10446</u>	<u>10470</u>
<u>10498</u>	<u>10482</u>	<u>10504</u>	<u>10506</u>	<u>10468</u>	<u>10491</u>	<u>10486</u>	<u>10501</u>	<u>10472</u>	<u>10485</u>	<u>10450</u>	<u>10473</u>	<u>10451</u>	<u>10478</u>	<u>10465</u>
<u>10502</u>	<u>10499</u>	<u>10467</u>	<u>10471</u>	<u>10490</u>	<u>10484</u>	<u>10476</u>	<u>10489</u>	<u>10503</u>	<u>10505</u>	<u>10454</u>	<u>10456</u>	<u>10487</u>	<u>10459</u>	<u>10483</u>