
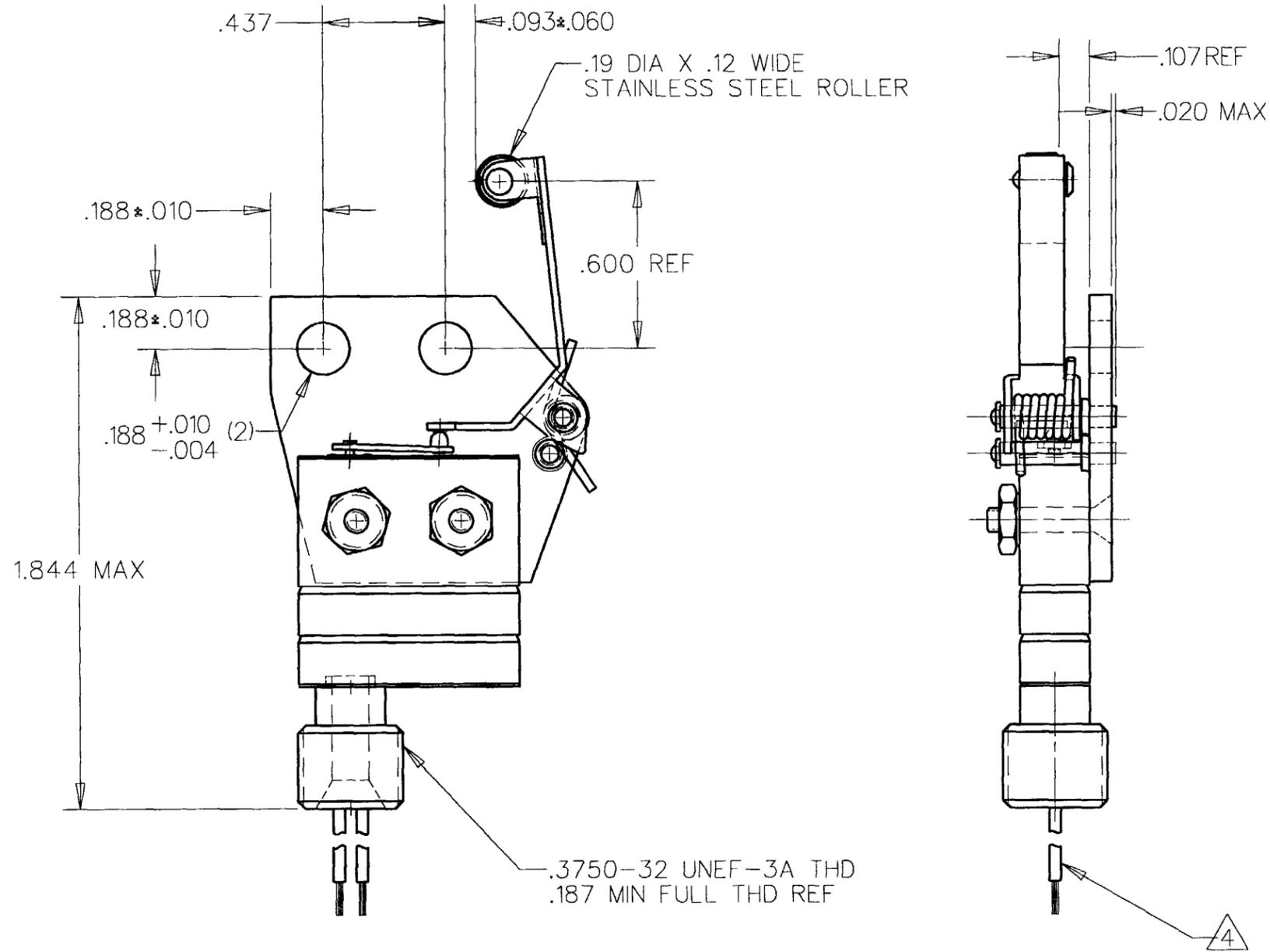


MICRO SWITCH
a Honeywell Division
FED. MFG. CODE 91929

SWITCH-BASIC

CATALOG LISTING
38HM10

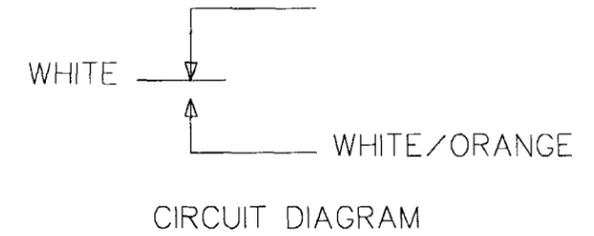

CATALOG LISTING
38HM10
PAGE 1 OF 1

REPLACES
PR-13215

ISSUE
M
5

REVISIONS

A	0069973	TSM	18 MAR 91
B	202458	CSL	27 FEB 01

CHECK

18 MAR 91

25 MAR 91


18 MAR 91

MASTER

DRAWN

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH

 THIRD ANGLE PROJECTION



SCALE 2:1

DO NOT SCALE PRINT

CHARACTERISTICS	
OPERATING FORCE	3 LBS MAX
RELEASE FORCE	6 OZ MIN
PRETRAVEL	.012 MIN
DIFFERENTIAL TRAVEL	.030 MAX
OVERTRAVEL	.050 MIN

ELECTRICAL DATA	
CONTACT ARRANGEMENT SPNO	
28 VOLTS DC RATING	
INDUCTIVE	SEA LEVEL --- 1/4 AMP 70,000 FT --- 1/4 AMP
RESISTIVE	SEA LEVEL --- 1 AMP 70,000 FT --- 1 AMP

UNLESS OTHERWISE SPECIFIED TOLERANCES ARE	
ONE PLACE	(.0) ± .030
TWO PLACE	(.00) ± .015
THREE PLACE	(.000) ± .005
ANGLES	±

WEIGHT

NOTES

- 1 - UNIT INCLUDES 8HM102 BASIC SWITCH
- 2 - SWITCH HERMETICALLY SEALED PER MIL-S-8805, SYMBOL 5
- 3 - ALL EXPOSED PARTS ARE CORROSION RESISTANT MATERIALS OR SURFACE TREATED
- 4 - LEADWIRE PER MIL-W-22759/10-20 AND 36 INCHES LONG REF

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[38HM10](#)