

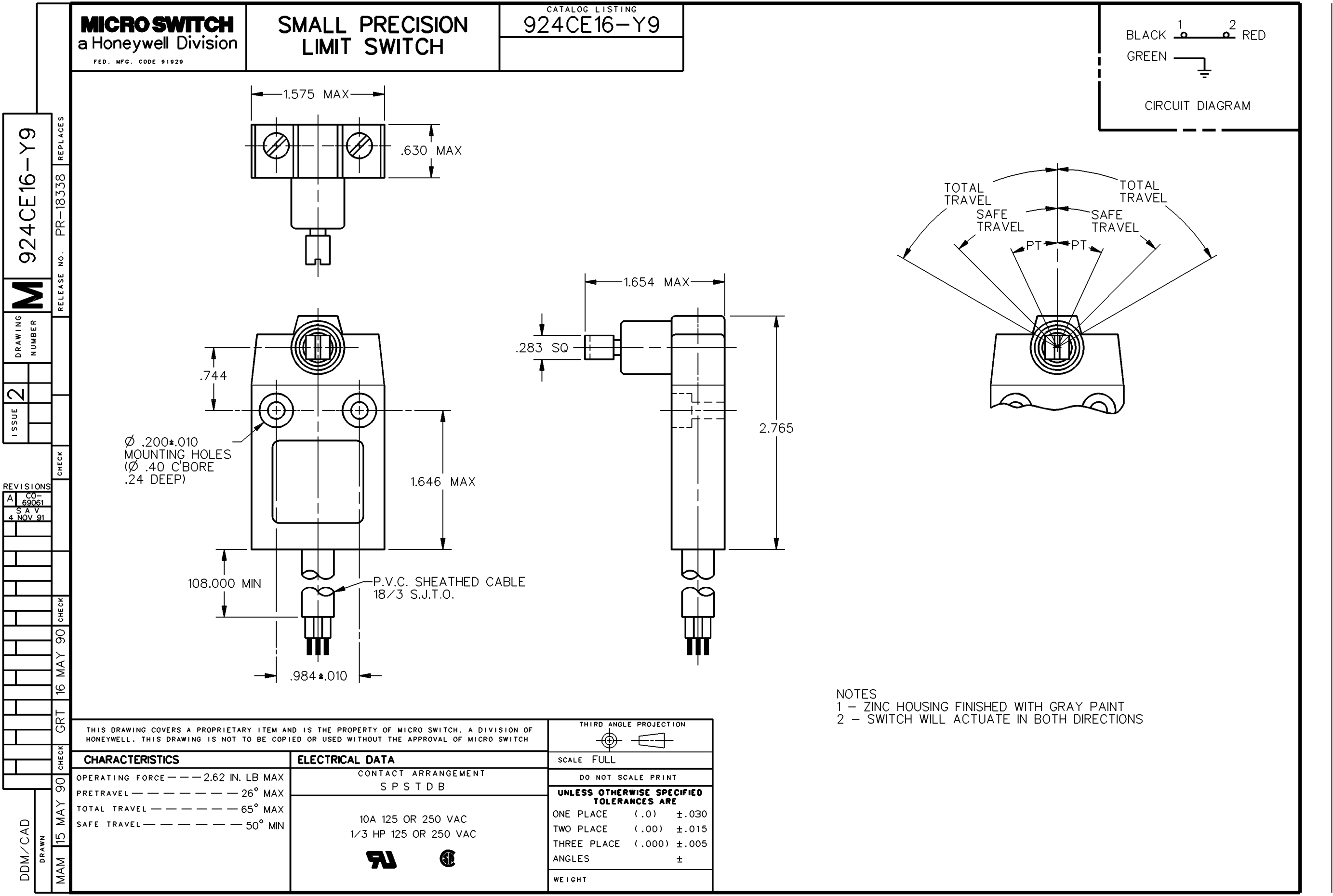


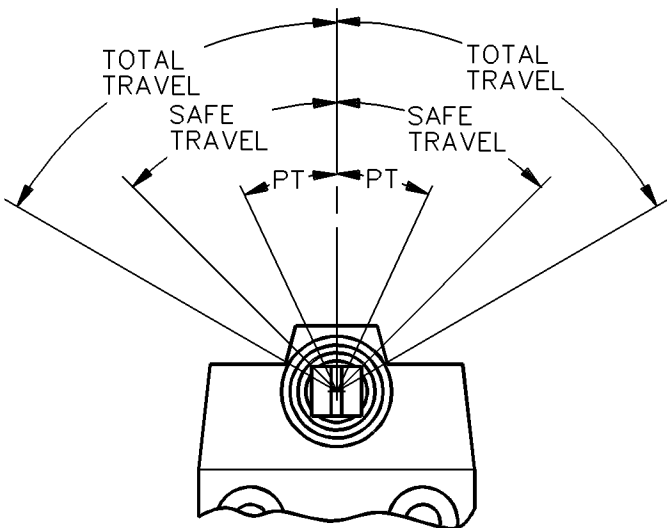

MICRO SWITCH
a Honeywell Division
FED. MFG. CODE 91929

**SMALL PRECISION
LIMIT SWITCH**

CATALOG LISTING
924CE16-Y9

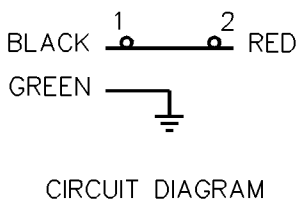

- NOTES
1 - ZINC HOUSING FINISHED WITH GRAY PAINT
2 - SWITCH WILL ACTUATE IN BOTH DIRECTIONS

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH

CHARACTERISTICS

OPERATING FORCE --- 2.62 IN. LB MAX
PRETRAVEL --- 26° MAX
TOTAL TRAVEL --- 65° MAX
SAFE TRAVEL --- 50° MIN

 
ELECTRICAL DATA

CONTACT ARRANGEMENT
S P S T D B

10A 125 OR 250 VAC
1/3 HP 125 OR 250 VAC



THIRD ANGLE PROJECTION



SCALE FULL

DO NOT SCALE PRINT

**UNLESS OTHERWISE SPECIFIED
TOLERANCES ARE**

ONE PLACE (.0) ±.030
TWO PLACE (.00) ±.015
THREE PLACE (.000) ±.005
ANGLES ±

WEIGHT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[924CE16-Y9](#)