



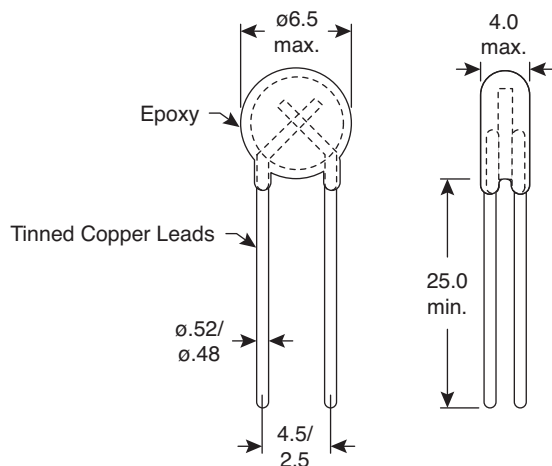

Dimensions (mm)
(min./max.)

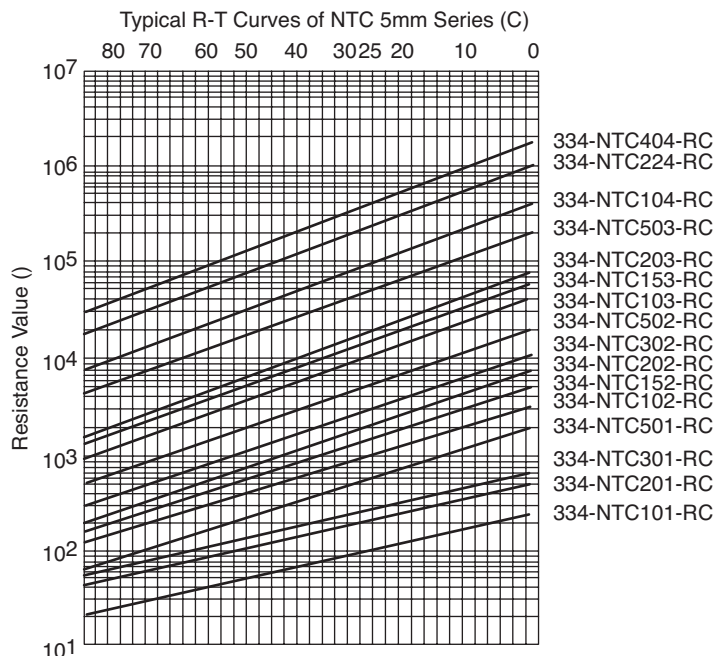

■ Specifications:

- Type: 5mm epoxy coated disc
- Operating temperature: -20°~+125°C
- RoHS Compliant
- Maximum power rating: 500mW
- Resistance tolerance: ±15%
- Thermal dissipation constant: 6mW/°C

Mouser Stock No.	Nominal Resistance @25°C(Ω)	Beta Value ±7%(°K)	Maximum Operating Current @25°C(mA)	Thermal Time Constant (Sec.)	Part Marking
334-NTC101-RC	100	3100	200	19	110
334-NTC201-RC	200	3000	200	14	120
334-NTC301-RC	300	3000	150	15	130
334-NTC501-RC	500	3800	100	16	150
334-NTC102-RC	1000	3700	80	17	210
334-NTC152-RC	1500	3700	60	14	215
334-NTC202-RC	2000	4000	60	14	220
334-NTC302-RC	3000	4000	50	14	230
334-NTC502-RC	5000	4100	45	15	250
334-NTC103-RC	10000	4100	30	15	310
334-NTC153-RC	15000	4200	25	18	315
334-NTC203-RC	20000	4200	25	18	320
334-NTC503-RC	50000	4400	20	18	350
334-NTC104-RC	100000	4400	15	16	410
334-NTC224-RC	220000	4500	6	20	422
334-NTC404 -RC	400000	4500	5	18	440

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Xicon:

[334-NTC404-RC](#) [334-NTC224-RC](#) [334-NTC153-RC](#) [334-NTC201-RC](#) [334-NTC503-RC](#) [334-NTC103-RC](#) [334-NTC102-RC](#) [334-NTC301-RC](#) [334-NTC502-RC](#) [334-NTC202-RC](#) [334-NTC203-RC](#) [334-NTC501-RC](#) [334-NTC101-RC](#) [334-NTC104-RC](#) [334-NTC152-RC](#) [334-NTC302-RC](#)