

Hybrid Couplers High Power 3 dB, 90°

Applications

- Microstrip Circuits
- Power Amps
- Dividers/Combiners
- Switch Networks
- Balanced Detectors
- Antenna Feeds

Features


- 0.225 – 0.4 GHz
- 2 – Way power Split
- Welded Tab mount
- Reliable Performance
- Handles 420 Watts
- Meets MIL-E-5400 Class 3 Requirements





NOTES: Anaren Power rating applies when solder tab/coupler interface has been conformally coated.

Electrical and Mechanical Specifications subject to change without notice.

Outline Drawing

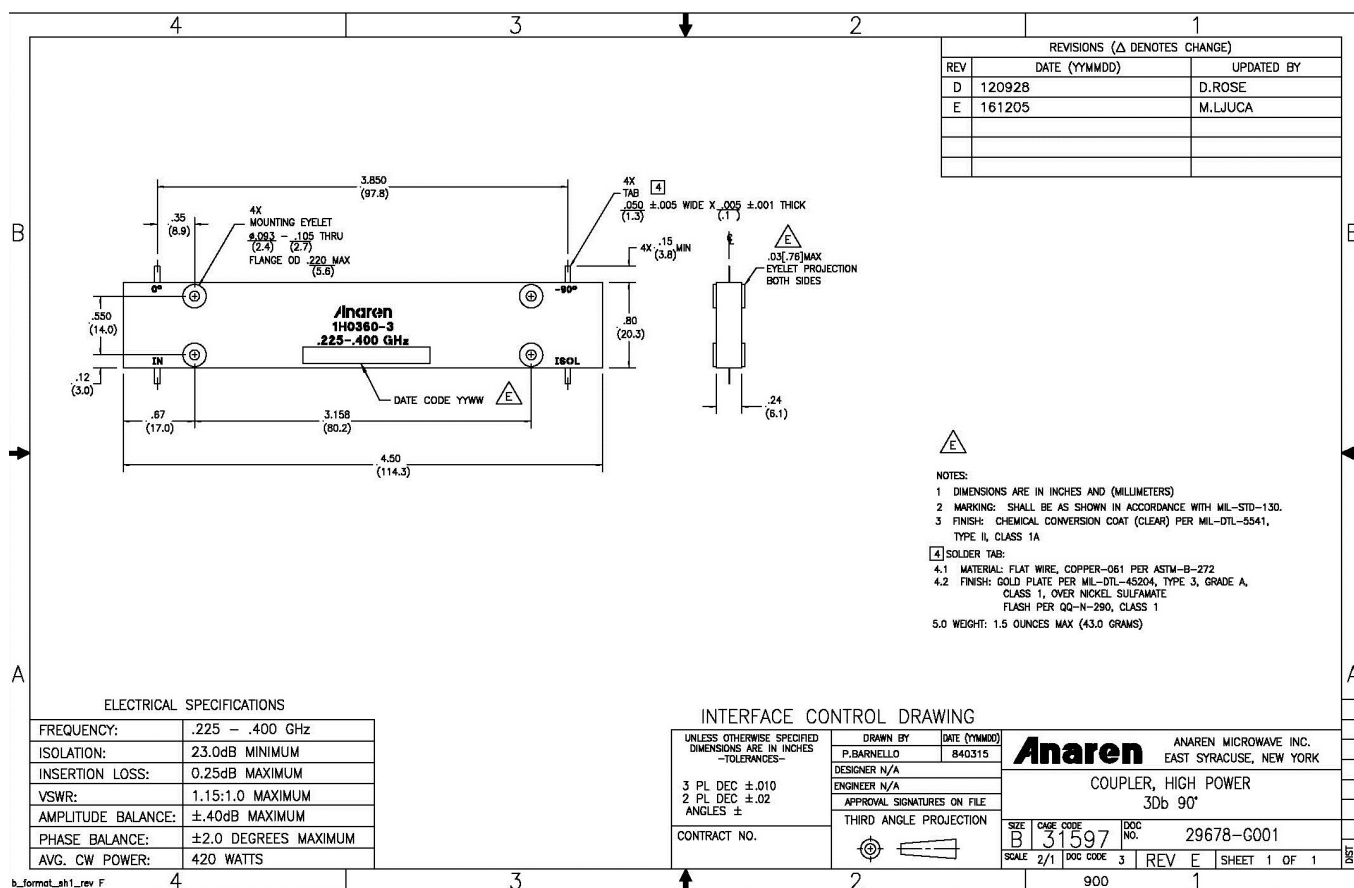

Typical Test Data Plots

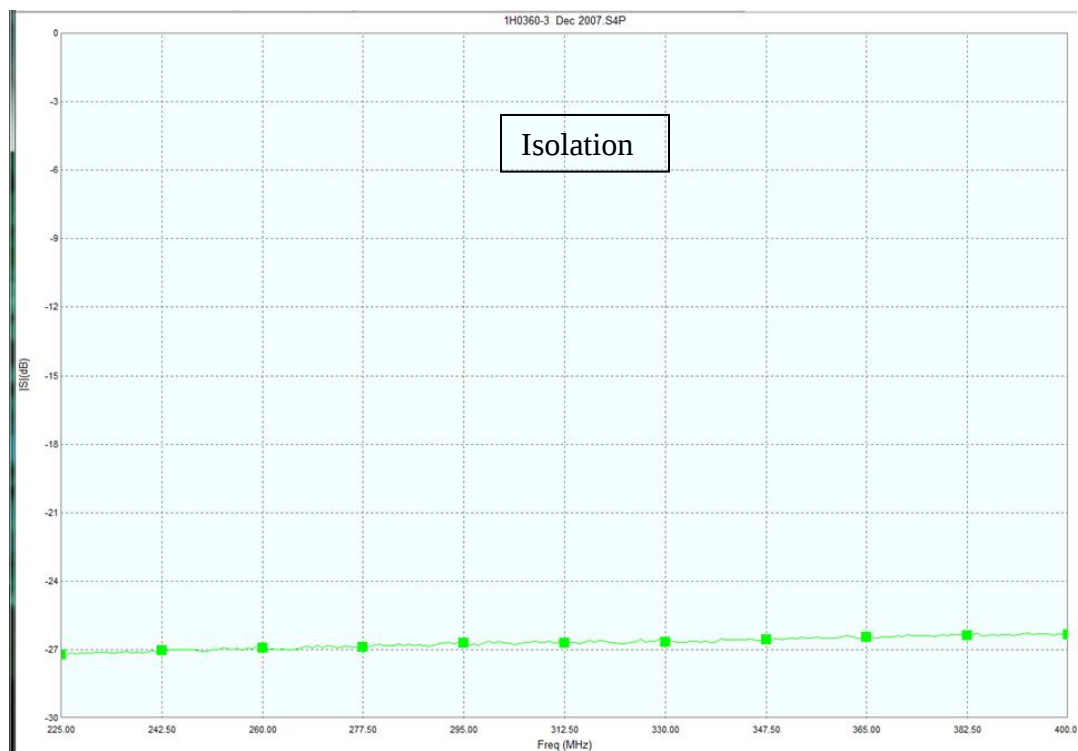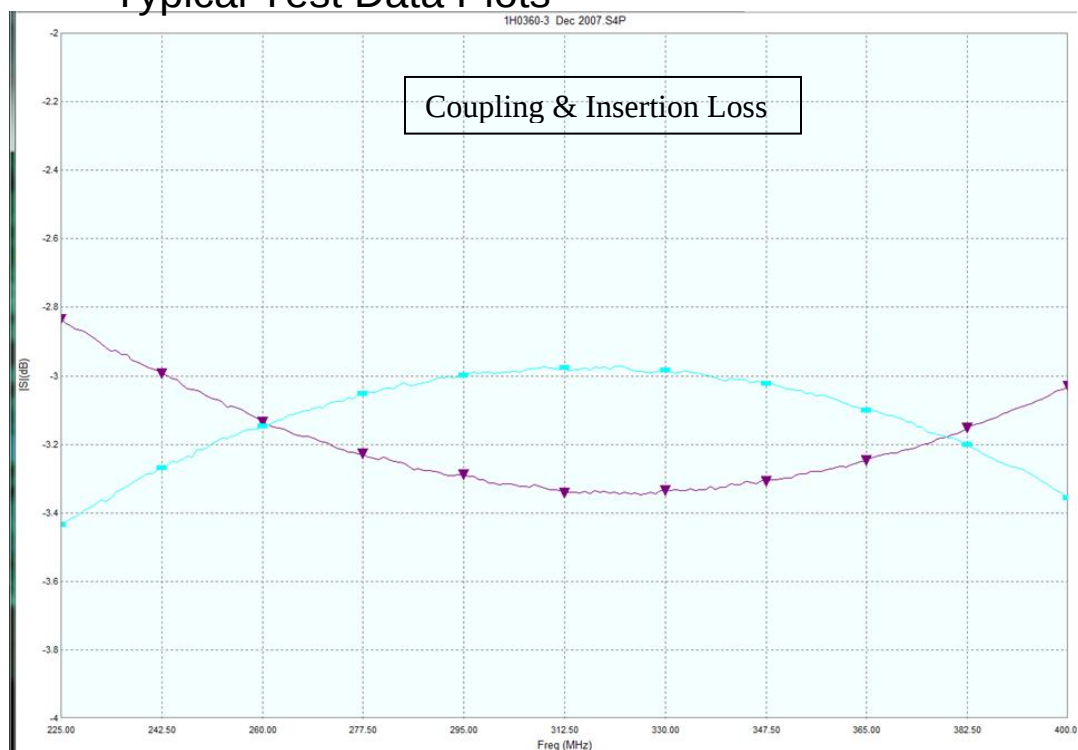

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Anaren:](#)

[1H0360-3](#)