


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0082248520](#)
Status: **Active**
Description: 2.50mm Pitch Round Conductor Flat Cable - 24 AWG (7 x 32) Stranded, Topcoat, 20 Circuits, Reel 30.48m Length

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	24492
Crimp Quality Equipment	Yes
Geographic Area	Asia
Product Name	Ribbon
UPC	800754373197
Physical	
Cable Length	30.48m
Circuits (Loaded)	20
Insulation	PVC
Packaging Type	Reel
Pitch - Termination Interface	2.50mm
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	24
Wire/Cable Type	(7x32) Stranded, Topcoat
Electrical	
Current - Maximum per Contact	N/A
Voltage - Maximum	300V
Material Info	
Engineering Number	24492-20-100B
Reference - Drawing Numbers	
Sales Drawing	SD-24492-001

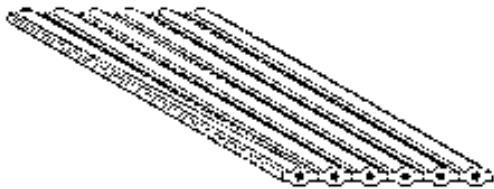

Series image - Reference only

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
Need more information on product environmental compliance?	
Email productcompliance@molex.com	
Please visit the Contact Us section for any non-product compliance questions.	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[24492](#) Series

Use With
[42219](#) SPOX IDT Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

82-24-8520