

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190070008

Status:


Active

Overview:

Standard Quick-Disconnect Terminals

Description:

Flag InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm²) Wire, Metal Strip, Tab 6.35 x 0.81mm

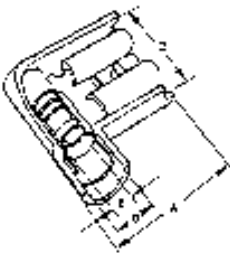

Series image - Reference only

- Documents:
- 3D Model

Product Specification PS-19902-011-001 (PDF)
- 3D Model (PDF)

Packaging Specification PK-19007-001-001 (PDF)
- Drawing (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification PS-19902-008-001 (PDF)

Agency Certification

CSA

LR18689

UL

E79133

General

Product Family

Quick Disconnects

Series

19007

Crimp Quality Equipment

Yes

Insulated

Fully

Overview

Standard Quick-Disconnect Terminals

Product Name

InsulKrimp

Type

Quick Disconnect

UPC

800753031500

Physical

Barrel Type

Closed

Color - Resin

Red

Flammability

94V-2

Gender

Female

Glow-Wire Capable

Yes

Insulation

Nylon (PA)

Lock to Mating Part

None

Material - Metal

Brass

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

Nylon

Net Weight

1.500/g

Orientation

Flag

Packaging Type

Reel

Polarized to Mating Part

No

Tab Thickness

0.81mm

Tab Width

6.35mm

Temperature Range - Operating

-65° to +105°C

Wire Insulation Diameter

4.44mm max.

Wire Size AWG

18, 20, 22

Electrical

Voltage - Maximum

600V

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Engineering Number

AA-2220Z

Reference - Drawing Numbers

EU ELV

Compliant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

D(2021)4569-DC (8

July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

19007 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

| Global                |           |
|-----------------------|-----------|
| Description           | Product # |
| Applicator Perishable | 192920015 |
| Tool Kit              |           |
| Mini-Mac Applicator   | 638026200 |
| Rear Feed             |           |

Packaging Specification  
Product Specification  
Sales Drawing

PK-19007-001-001  
PS-19902-008-001, PS-19902-011-001  
SD-19007-004-001

This document was generated on 09/13/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19007-0008](#)