


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190670131](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: NylaKrimp Funnel Entry Ring Tongue Terminal for 4/0 AWG Wire, Stud Size 5/8" (M16)

Documents:
[3D Model](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Product Specification PS-19902-016-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification	
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19067
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	NylaKrimp
Type	Ring
UPC	800755967197
Physical	
Barrel Type	Closed - Brazed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	5/8" (M16)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	23.98mm max.
Wire Size AWG	4/0
Material Info	
Engineering Number	L-995-58
Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-013-001, PS-19902-016-001
Sales Drawing	SD-19067-009

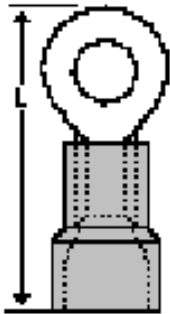

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Not Reviewed REACH SVHC Not Contained Per - ED/30/2017 (7 July 2017) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[19067 Series](#)

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Die Set (large) for the HHLS Hydraulic Crimper	192890031

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19067-0131](#)