

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190670369](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: NylaKrimp Funnel Entry Ring Tongue Terminal for 4/0 AWG Wire, Stud Size 5/16" (M8)


Documents:
[3D Model](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Product Specification PS-19902-016-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

General
Product Family Ring and Spade Terminals
Series [19067](#)
Crimp Quality Equipment Yes
Overview [Solderless Terminals](#)
Product Name NylaKrimp
Type Ring
UPC 822350727082

Physical
Barrel Type Closed - Brazed
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 51.570/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 5/16" (M8)
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 23.98mm max.
Wire Size AWG 4/0

Material Info
Engineering Number L-995-56

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001,
PS-19902-016-001
Sales Drawing SD-19067-009

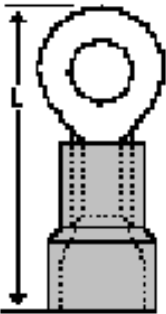

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/30/2017 (7 July 2017)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19067 Series](#)

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Die Set (large) for the HHLS Hydraulic Crimper	192890031

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19067-0369