

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191180058](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 10 (M5)

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[3D Model \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)
[Packaging Specification PK-19902-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series [19118](#)
Crimp Quality Equipment Yes
Overview [Solderless Terminals](#)
Product Name Krimptite
Type Spade
UPC 800755082647

Physical
Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Net Weight 0.965/g
Packaging Type Bag
Plating min - Mating 4.064µm
Plating min - Termination 4.064µm
Stud Size 10 (M5)
Wire Size AWG 14, 16
Wire Size mm² 1.00-2.50

Material Info
Engineering Number BB-116-10

Reference - Drawing Numbers
Packaging Specification PK-19902-001-001
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19118-001-001

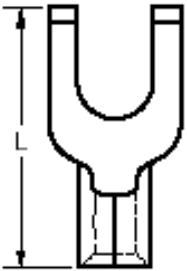

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19118 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19118-0058