

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191470007](#)
Status: **Active**
Overview: [VersaKrimp Terminals and Splices](#)
Description: VersaKrimp Block Spade Terminal for 18-22 AWG Wire

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series [19147](#)
Crimp Quality Equipment Yes
Overview [VersaKrimp Terminals and Splices](#)
Product Name VersaKrimp
Type Spade
UPC 800753106581

Physical
Barrel Type Closed - Brazed
Insulation None
Material - Plating Mating Tin
Net Weight 0.476/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 5-6 (M3-3.5)
Termination Interface: Style Crimp or Compression
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Material Info
Engineering Number AA-334-06T

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-015-001
Sales Drawing AACD30301-001

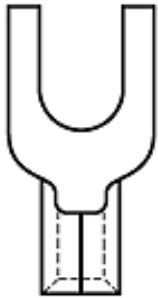

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[19147 Series](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	190270034
Mini-Mac Applicator	638853800

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19147-0007