


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395040605](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 3.50mm Pitch Eurostyle Horizontal Plug, with Retention Screws and Standard Imprinting, Gold (Au) Plated, 5 Circuits

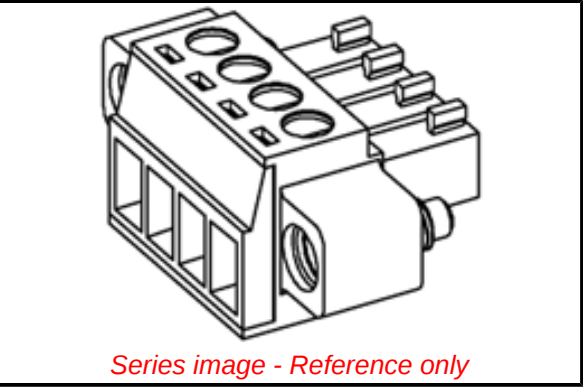

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[3D Model \(PDF\)](#)
[Product Specification PS-39500-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
UL E48521
General
Product Family Terminal Blocks
Series [39504](#)
Application N/A
Comments with Standard Imprinting
Component Type Plug
Overview [Eurostyle Terminal Blocks](#)
Product Name ESE, Eurostyle Pluggable
Type Euro Block
UPC 822350442022

Physical
Circuits (Loaded) 5
Entry Angle Vertical
Lock to Mating Part Yes
Number of Rows 1
Orientation Horizontal
Panel Mount No
Pitch - Mating Interface 3.50mm
Pitch - Termination Interface 3.50mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C
Wire Size AWG 16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm² 0.05-1.31

Electrical
Current - Maximum per Contact 8.0A
Voltage - Maximum 300V

Material Info

Reference - Drawing Numbers
Product Specification PS-39500-001-001
Sales Drawing SD-39504-001

EU ELV
Not Relevant

EU RoHS **China RoHS**
Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed
For more information, please visit [Contact US](#)

China ROHS Not Relevant
ELV Not Relevant
RoHS Phthalates Not Reviewed

Search Parts in this Series
[39504](#) Series

Mates With
Most 3.50mm Pitch Industry Standard PCB Headers, [39505](#) Vertical PCB Header with Threaded Retention Inserts, [39506](#) Horizontal PCB Header with Threaded Retention Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39504-0605](#)