

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395161512

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

3.81mm Pitch Eurostyle Horizontal PCB Header, with Threaded Retention Inserts, Gold (Au) Plated, 12 Circuits

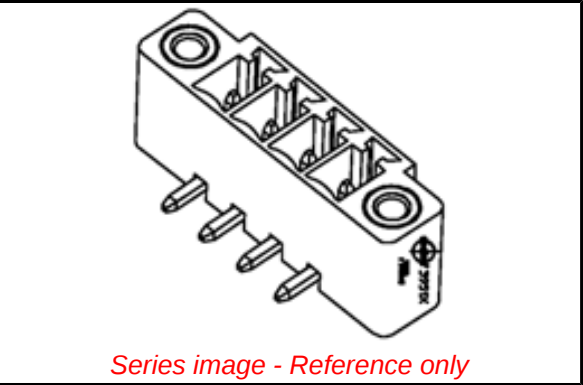

Documents:	
3D Model	Product Specification PS-39500-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-39516-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39516
Application	N/A
Component Type	PCB Header
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350444705
Physical	
Circuits (Loaded)	12
Entry Angle	N/A
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Horizontal
PC Tail Length	3.50mm
PCB Thickness - Recommended	2.50mm
Panel Mount	No
Pitch - Mating Interface	3.81mm
Pitch - Termination Interface	3.81mm
Polarized to Mating Part	Yes
Shrouded	Fully
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Electrical	
Current - Maximum per Contact	8.0A
Voltage - Maximum	300V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-39516-001-001
Product Specification	PS-39500-001-001
Sales Drawing	SD-39501-002, SD-39516-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[39516](#) Series

Mates With

Most 3.81mm Pitch Industry Standard Plugs, [39517](#) Vertical Plug with Retention Screws, [39514](#) Horizontal Plug with Retention Screws

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39516-1512](#)