

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395200611

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.00mm Pitch Eurostyle Horizontal Plug, with Standard Imprinting, Gold (Au) Plated, 11 Circuits

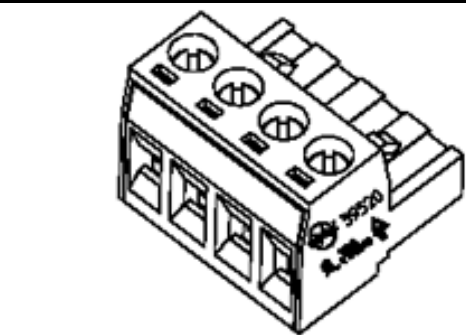

Series image - Reference only

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

|                               |                                |
|-------------------------------|--------------------------------|
| Agency Certification          |                                |
| UL                            | E48521                         |
| General                       |                                |
| Product Family                | Terminal Blocks                |
| Series                        | 39520                          |
| Application                   | N/A                            |
| Comments                      | with Standard Imprinting       |
| Component Type                | Plug                           |
| Overview                      | Eurostyle Terminal Blocks      |
| Product Name                  | ESE, Eurostyle Pluggable       |
| Type                          | Euro Block                     |
| UPC                           | 822350469456                   |
| Physical                      |                                |
| Circuits (Loaded)             | 11                             |
| Entry Angle                   | Vertical                       |
| Lock to Mating Part           | Yes                            |
| Number of Rows                | 1                              |
| Orientation                   | Horizontal                     |
| Panel Mount                   | No                             |
| Pitch - Mating Interface      | 5.00mm                         |
| Pitch - Termination Interface | 5.00mm                         |
| Polarized to Mating Part      | Yes                            |
| Stackable                     | No                             |
| Temperature Range - Operating | -40° to +105°C                 |
| Wire Size AWG                 | 12, 14, 16, 18, 20, 22, 24, 26 |
| Wire Size mm²                 | 0.13-3.31                      |
| Electrical                    |                                |
| Current - Maximum per Contact | 18.0A                          |
| Voltage - Maximum             | 300V                           |
| Material Info                 |                                |
| Reference - Drawing Numbers   |                                |
| Product Specification         | PS-39500-001-001               |
| Sales Drawing                 | SD-39520-001                   |

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

39520 Series

Mates With

39521 Vertical PCB Header, 39522 Horizontal PCB Header, Most 5.00mm Pitch Industry Standard PCB Headers, 39528 Dual Level PCB Header, Open Ends

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39520-0611](#)