

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0399500103

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

8.00mm Pitch Beau Eurostyle Fixed Mount, High Voltage PCB Terminal Block, Vertical, 3 Circuits

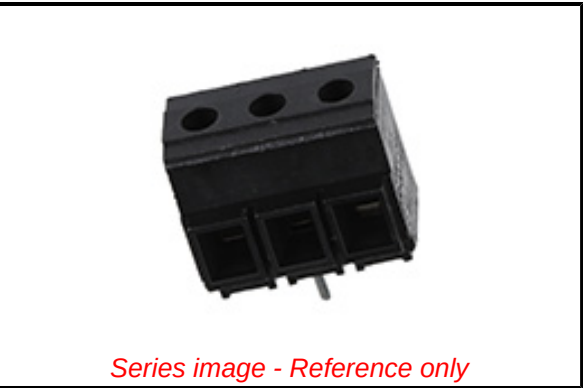

Series image - Reference only

Documents:	
Drawing (PDF)	3D Model (PDF)
3D Model	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39950
Application	N/A
Comments	High Power
Component Type	One Piece
Overview	Eurostyle Terminal Blocks
Product Name	Eurostyle Fixed Mount
Type	Euro Block
UPC	800753318618
Physical	
Circuits (Loaded)	3
Entry Angle	Horizontal
Flammability	94V-0
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Number of Rows	1
Orientation	Vertical
PC Tail Length	4.06mm
PCB Retention	None
PCB Thickness - Recommended	2.60mm
Panel Mount	No
Pitch - Mating Interface	8.00mm
Pitch - Termination Interface	8.00mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to Mating Part	N/A
Stackable	No
Temperature Range - Operating	130°C
Wire Size AWG	12, 14, 16, 18, 20, 22
Wire Size mm²	0.50-4.00
Electrical	
Current - Maximum per Contact	20.0A
Voltage - Maximum	600V
Solder Process Data	
Lead-freeProcess Capability	WAVE
Material Info	
Engineering Number	950503

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

39950 Series

Reference - Drawing Numbers
Sales Drawing

SD-39950-001-001

This document was generated on 09/13/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39950-0103](#)