

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0500588000**
Status: **Active**
Overview: PicoBlade Connector System
Description: 1.25mm Pitch PicoBlade Crimp Terminal, Female, 28-32 AWG, Reel

Documents:

3D Model	Product Specification PS-51021-024-001 (PDF)
Drawing (PDF)	Product Specification PS-51021-026-001 (PDF)
Product Specification PS-51021-001-001 (PDF)	Product Specification PS-51021-027-001 (PDF)
Product Specification PS-51021-002-001 (PDF)	Product Specification PS-51021-032-001 (PDF)
Product Specification PS-51021-009-001 (PDF)	Application Specification 510210000-AS-000 (PDF)
Product Specification PS-51021-010-001 (PDF)	Application Specification 510210001-AS-000 (PDF)
Product Specification PS-51021-011-001 (PDF)	Packaging Specification 500589200SPK-200 (PDF)
Product Specification PS-51021-022-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-51021-023-001 (PDF)	

General

Product Family	Crimp Terminals
Series	50058
Application	Signal, Wire-to-Board, Wire-to-Wire
Crimp Quality Equipment	Yes
Current Derating Order No	987651-3691
Overview	<u>PicoBlade Connector System</u>
Packaging Alternative	50058-8100 (Loose)
Product Name	PicoBlade
UPC	800753576315

Physical

Durability (mating cycles max)	30
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	12.600/mg
Packaging Type	Reel
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.50-1.00mm
Wire Size AWG	28, 30, 32
Wire Size mm ²	N/A


Electrical

Current - Maximum per Contact	1.0A
Voltage - Maximum	125V

Material Info

Reference - Drawing Numbers

Application Specification	510210000-AS-000, 510210001-AS-000
Crimp Specification	500580000-CS-000
Packaging Specification	500589200SPK-200
Product Specification	PS-51021-001-001, PS-51021-002-001, PS-51021-009-001, PS-51021-010-001, PS-51021-011-001, PS-51021-022-001, PS-51021-023-001, PS-51021-024-001, PS-51021-026-001, PS-51021-027-001, PS-51021-032-001

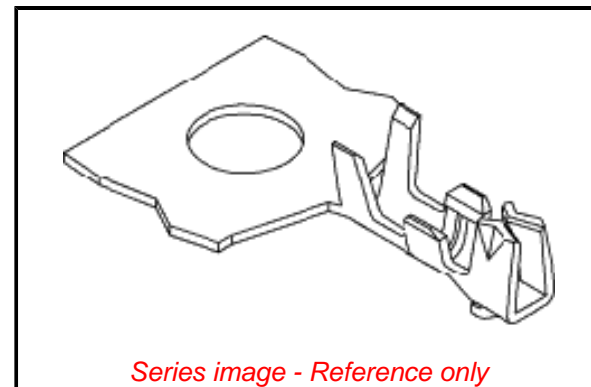

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

50058 Series

Mates With

50125 Crimp Terminal 26-28 AWG, 50133
Crimp Terminal 28-32 AWG

Use With

51021 PicoBlade Wire-to-Wire and Wire-to-
Board Housing

This document was generated on 11/02/2018

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[50058-8000](#) [50058-8000 \(Cut Strip\)](#) [50058-8000 \(Mouser Reel\)](#)