

SMD Power Inductor CDRH50D23/A



Description

- Ferrite drum core construction.
- Magnetically shielded.
- L × W × H: 5.5 × 5.6 × 2.5 mm Max.
- Product weight: 0.2g(Ref.)
- Moisture Sensitivity Level: 1
- RoHS compliance.
- Qualified to AEC-Q200.

Environmental Data

- Operating temperature range: -40°C ~ +125°C (including coil's self temperature rise)
- Storage temperature range: -40°C ~ +125°C
- Solder reflow temperature: 260 °C peak.


Packaging

- Carrier tape and reel packaging
- 11.8" diameter reel
- 2000 pcs per reel

Applications


- Automotive and other high temperature, high reliability application.

Dimension - [mm]

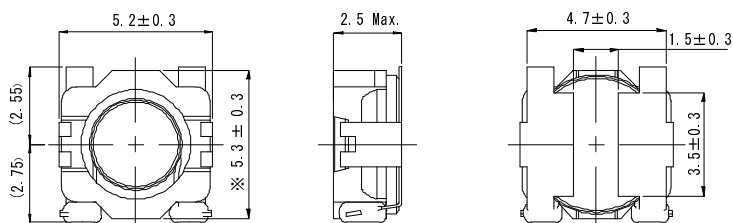

※ that including the solder icicles.

Land pattern and Schematics - [mm]

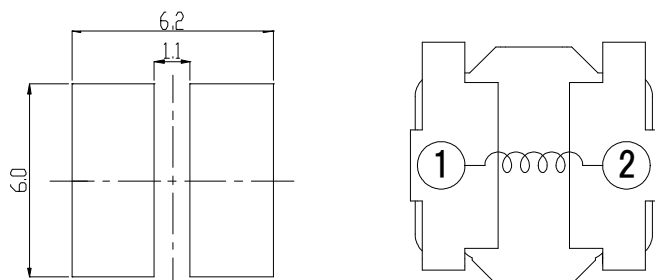

Electrical Characteristics

Part No.	Stamp	Inductance (μ H) 100kHz [Within]	D.C.R.(m Ω) [Max.] (at 20°C)※1	Rated current (A) (at 125°C)※2
CDRH50D23ANP-4R7NC	A	4.7 ± 30%	84(67)	1.23
CDRH50D23ANP-6R8NC	B	6.8 ± 30%	124(99)	0.96
CDRH50D23ANP-100NC	C	10 ± 30%	189(151)	0.82
CDRH50D23ANP-150NC	D	15 ± 30%	305(244)	0.68
CDRH50D23ANP-220NC	E	22 ± 30%	390(312)	0.53

※ 1.() are typical value.






※ 2.The rated DC Current indicates the DC current when the inductance decreases to maximum 65% of nominal value or DC current when the temperature of coil is increased to 30°C. The smaller one is defined as DC rated current.

SMD Power Inductor CDRH50D23/A




Saturation Current & Temperature Rise Graph


— L (20°C) — ΔT

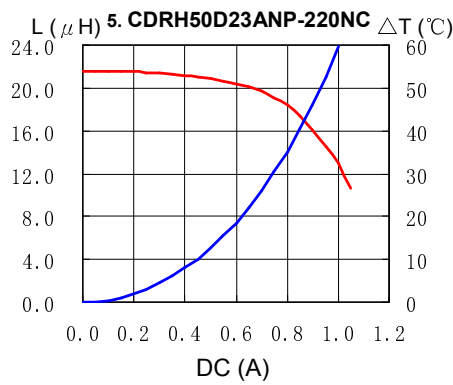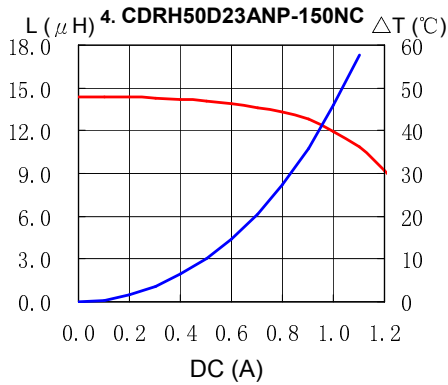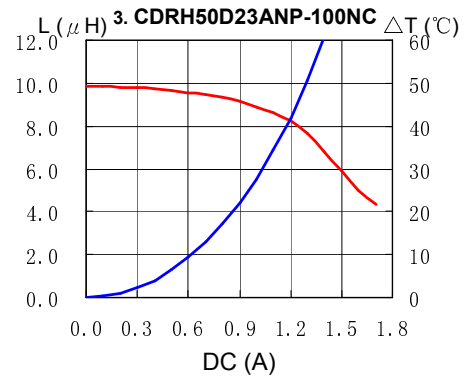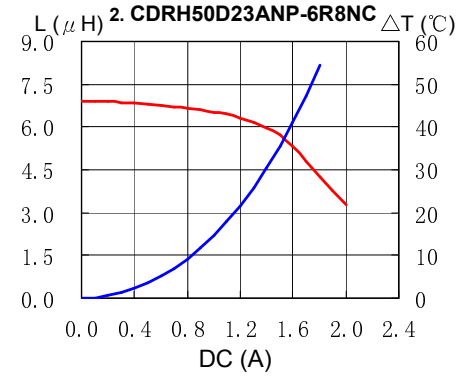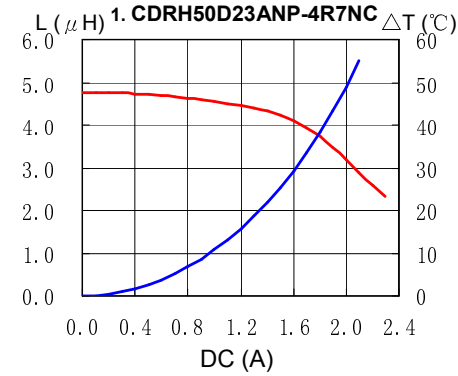

Solder Reflow Condition Heat Endurance

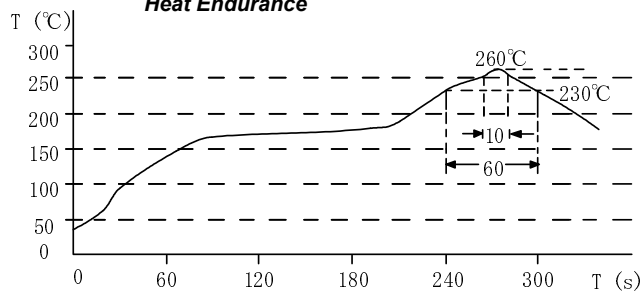

Temperature Chart

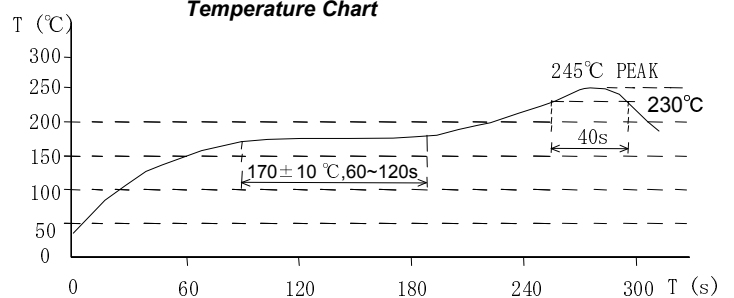

Please refer to the sales offices on our website - <http://www.sumida.com>

Hong Kong

Tel. +852-2880-6781
FAX. +852-2565-9600
sales@hk.sumida.com

Saitama(Japan)

Tel. +81-48-691-7300
FAX. +81-48-691-7340
sales@jp.sumida.com

Chicago

Tel. +1-847-545-6700
FAX. +1-847-545-6720
sales@us.sumida.com

Shanghai

Tel. +86-21-5836-3299
FAX. +86-21-5836-3266
shanghai.sales@cn.sumida.com

Seoul

Tel. +82-2-6237-0777
FAX. +82-2-6237-0778
sales@kr.sumida.com

Obernzell

Tel. +49-8591-937-0
FAX. +49-8591-937-103
contact@eu.sumida.com

Shenzhen

Tel. +86-755-8291-0228
FAX. +86-755-8291-0338
shenzhen.sales@cn.sumida.com

Singapore

Tel. +65-6296-3388
FAX. +65-6841-4426
sales@sg.sumida.com

Neumarkt

Tel. +49-9181-4509-110
FAX. +49-9181-4509-310
infocomp@eu.sumida.com

Taipei

Tel. +886-2-8751-2737
FAX. +886-2-8751-2738
sales@tw.sumida.com

San Jose

Tel. +1-408-321-9660
FAX. +1-408-321-9308
sales@us.sumida.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Sumida:

[CDRH50D23ANP-100NC](#)

[CDRH50D23ANP-220NC](#)

[CDRH50D23ANP-4R7NC](#)

[CDRH50D23ANP-6R8NC](#)