

C0603C0G1H150J030BA

TDK Item Description : C0603C0G1H150J****



Application & Main Feature

Commercial Grade (General (Up to 50V))

Series

C0603 [EIA CC0201]



Dimensions

L 0.60mm +/-0.03mm
W 0.30mm +/-0.03mm
T 0.30mm +/-0.03mm
B 0.10mm Min.
G 0.20mm Min.

Temperature Characteristic

C0G (-55 to 125 degC 0+/-30ppm/degC)

Rated Voltage

1H (50Vdc)

Capacitance

15pF

Capacitance Tolerance

J (+/-5%)

O Factor

700 Min.


Insulation Resistance

10Gohm Min.

AEC-Q200

Not Applicable


|Z|, ESR vs. Freq. Characteristics

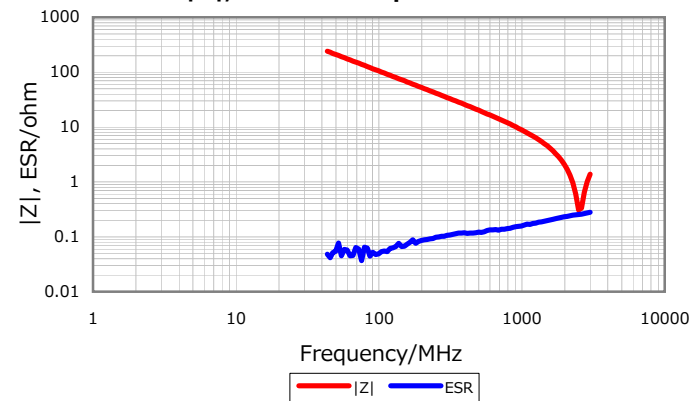


DC Bias Characteristic



Cap. vs. Freq. Characteristic

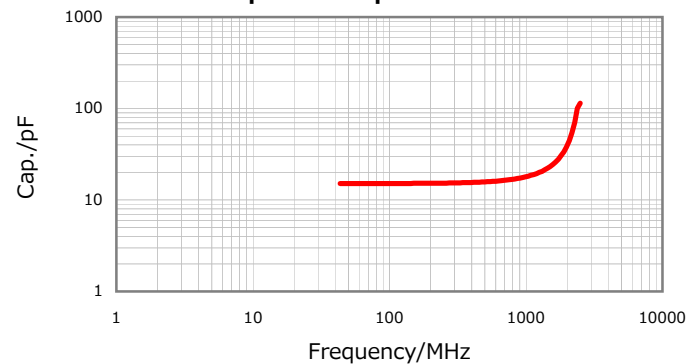

Temperature Characteristic

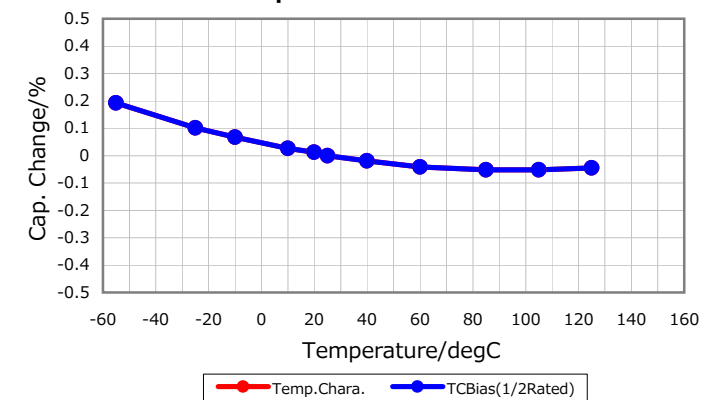

All specifications are subject to change without notice.

February 3, 2014

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

TDK:

[C0603C0G1H150J030BA](#)